

Sales Outline DrawingRevision: **A****Specifications:**

May not be suitable for all Medical and Aerospace applications.

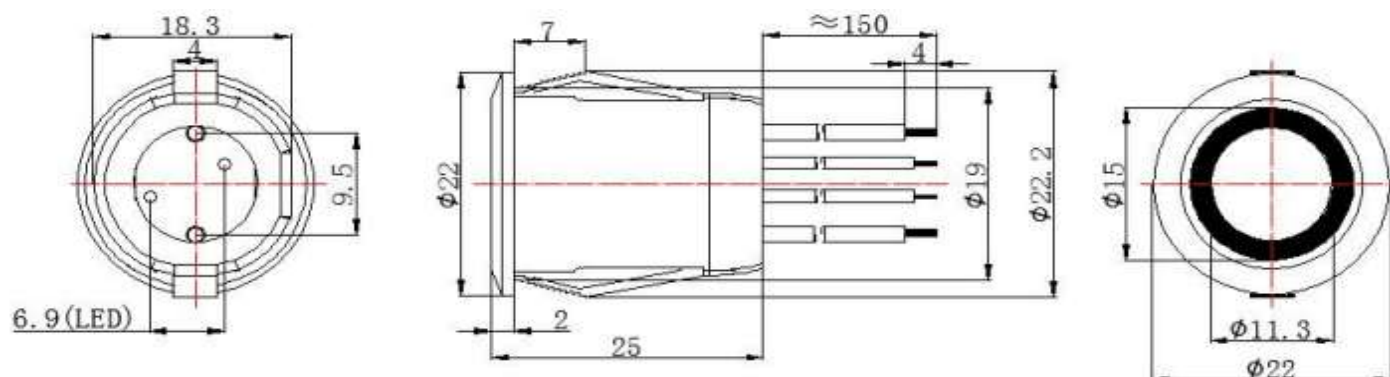
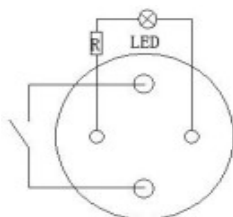
Contact Mallory Sonalert to discuss your application.

Panel Hole (mm)	19 mm
Switch Rated Voltage (VDC / VAC)	36 / 250
Switch Rated Current (A) DC / AC	5 / 5
LED Rated Voltage (VDC)	21.6-26.4
LED Rated Current (mA)	≤20
Button Color	Green
Switch Function	OFF=MOM
Circuit	SPST 1NO
Storage & Operating Temperature	-25 °C to +85 °C
Ingress Protection Rating	IP65
Shock Resistance	IK08
Material	PC Plastic, PA66+GF20%, Stainless
Termination Type	Wires
Wire Specification	7.3" (185 mm) PVC AWG18

RoHS Compliant**Part Number:****FPPQ19-FW1-S0M4G24***

* NOTES LED COLOR & VDC

R	RED
G	GREEN
B	BLUE
Y	YELLOW
W	WHITE
BLANK	CLEAR

Dimensions (mm):**CONNECTION DIAGRAM:****PANEL HOLE:**