

Sales Outline Drawing


Revision: **A**

Specifications:

May not be suitable for all Medical and Aerospace applications.
Contact Mallory Sonalert to discuss your application.

Panel Hole (mm)	16 mm
Switch Rated Voltage VDC/AC	36 / 250
Switch Rated Current ADC/AC	3 / 3
LED Rated Voltage VDC/AC	12
LED Rated Current mA DC/AC	10
LED Color	RED
Switch Function	ON-ON
Circuit	SPDT 1NO1NC
Operating Temperature	-25 °C to 85 °C
Ingress Protection Rating	IP65
Shock Resistance	IK09
Material, Light Ring	PC Plastic
Material, Button	Aluminum alloy (red anodized surface)
Material, Base	PC Plastic
Material, Gasket	SIL silica gel
Material, Nut	H59 Brass
Material, Housing	PBT
Termination Type	Solder Lugs

RoHS Compliant

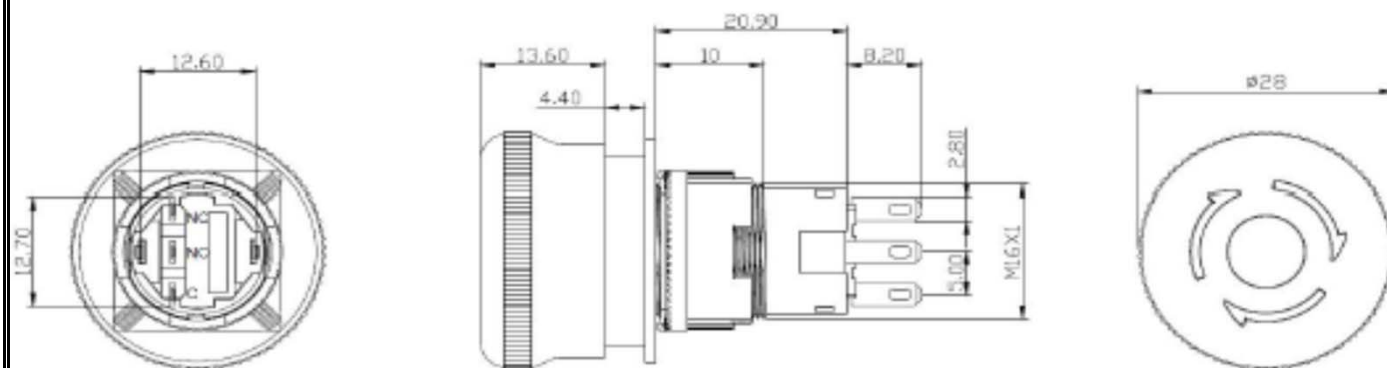

CONNECTION DIAGRAM:

PANEL HOLE:

