


Sales Outline Drawing

Specifications:

May not be suitable for all Medical and Aerospace applications.
Contact Mallory Sonalert to discuss your application.

Panel Hole (mm)	16 mm
Switch Rated Voltage VDC/AC	36 / 250
Switch Rated Current ADC/AC	5 / 5
Switch Function	ON-ON
Circuit	DPDT 2NO2NC
Operating Temperature	-25 °C to 65 °C
Ingress Protection Rating	IP65
Shock Resistance	IK09
Material, Button	Aluminum alloy (red anodized surface)
Material, Base	Stainless Steel
Material, Gasket	SIL silica gel
Material, Nut	H59 Brass
Material, Housing	PA66+GF20% Nylon
Termination Type	Solder Lugs

RoHS Compliant

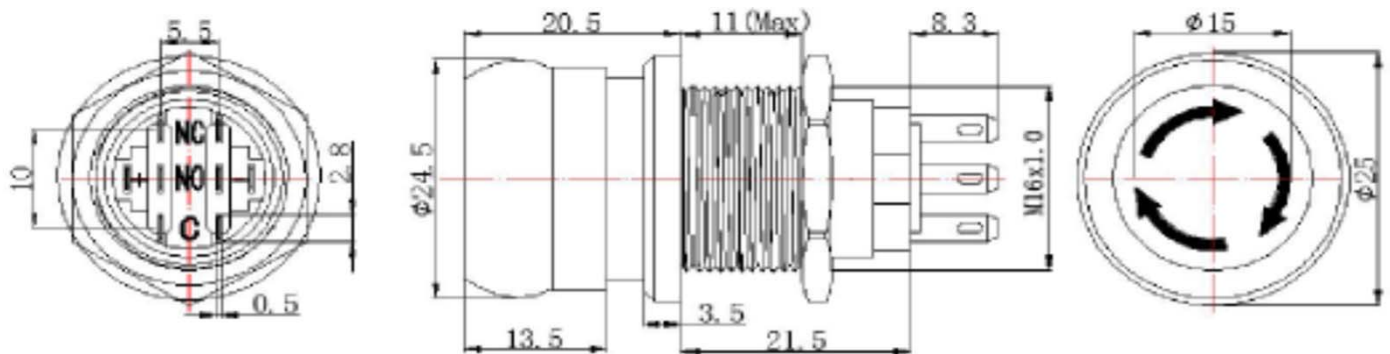

CONNECTION DIAGRAM:

PANEL HOLE:

