



Mallory Sonalert Products, Inc.

Part #: **FWCM12-BJA-S0M2B**

Sales Outline Drawing

Revision: **A**

Specifications:

May not be suitable for all Medical and Aerospace applications.
Contact Mallory Sonalert to discuss your application.

Panel Hole	12 mm
Rated Voltage (VDC / VAC)	36 / 250
Rated Current (A) DC / AC	2 / 1
Button Color	Blue
Switch Function	OFF-MOM
Circuit	SPST 1NO
Storage & Operating Temperature	-25 °C to +85 °C
Ingress Protection Rating	IP65
Shock Resistance	IK08
Material	ABS, PA66+GF20%, Stainless
Termination Type	Solder Lug

RoHS Compliant


Part Number:

FWCM12-BJA-S0M2B-*


* NOTES BUTTON COLOR

B	BLUE
BL	BLACK
G	GREEN
R	RED
W	WHITE
Y	YELLOW
BLANK	CLEAR

Dimensions (mm):

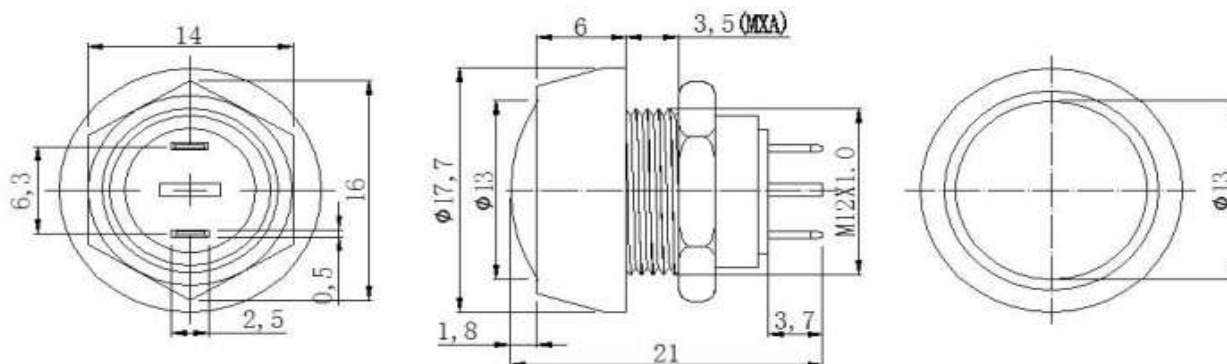

CONNECTION DIAGRAM:

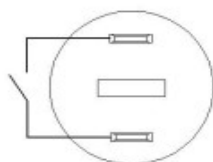

PANEL HOLE:

