

**Sales Outline Drawing**

**Specifications:**

May not be suitable for all Medical and Aerospace applications.  
Contact Mallory Sonalert to discuss your application.

Panel Hole	12 mm
Rated Voltage (VDC / VAC)	36 / 250
Rated Current (A) DC / AC	2 / 1
Button Color	Yellow
Switch Function	OFF-MOM
Circuit	SPST 1NO
Storage & Operating Temperature	-25 °C to +85 °C
Ingress Protection Rating	IP65
Shock Resistance	IK08
Material	ABS, PA66+GF20%, Stainless
Termination Type	Solder Lug

**RoHS Compliant**


**Part Number:**

**FWCM12-BJA-S0M2Y-\***


\* NOTES BUTTON COLOR

- B BLUE
- BL BLACK
- G GREEN
- R RED
- W WHITE
- Y YELLOW
- BLANK CLEAR

**Dimensions (mm):**

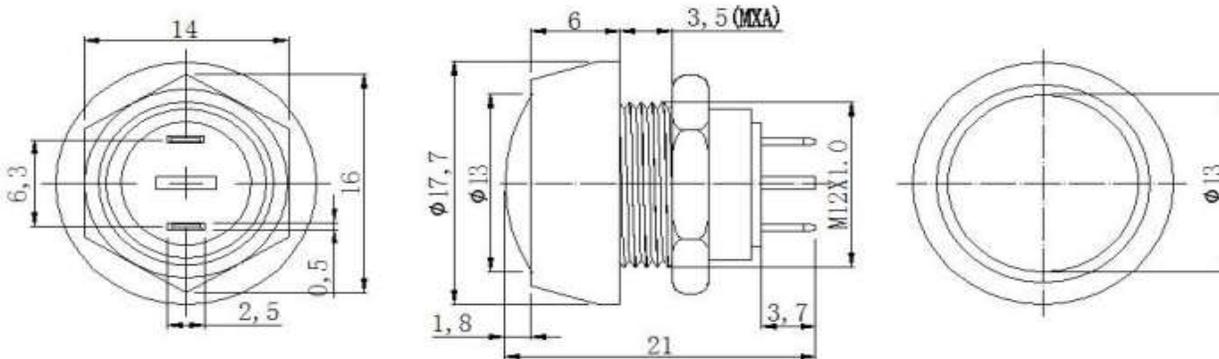

**CONNECTION DIAGRAM:**

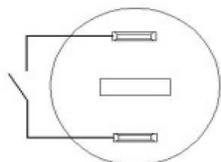

**PANEL HOLE:**

