



Mallory Sonalert Products, Inc.

Part #:

FWM16-FJ1-A1M3

Sales Outline Drawing

Revision:

A


May not be suitable for all Medical and Aerospace applications.
Contact Mallory Sonalert to discuss your application.

Specifications:

Panel Hole	16 mm
Rated Voltage (VDC / VAC)	36 / 250
Rated Current (A) DC / AC	5 / 5
Switch Function	ON-MOM
Circuit	SPDT 1NO1NC
Storage & Operating Temperature	-25 °C to +85 °C
Ingress Protection Rating	IP65
Shock Resistance	IK09
Certifications	UL, cUL listed under Series FLM16-FJ-1
Material, Button	Black aluminum Alloy
Material, Shell	Black aluminum Alloy
Material, Ring	Silica Gel
Material, Nut	H59 Brass
Material, Housing	PA66+GF20%
Termination Type	Solder Lug

Dimensions (mm):

RoHS Compliant

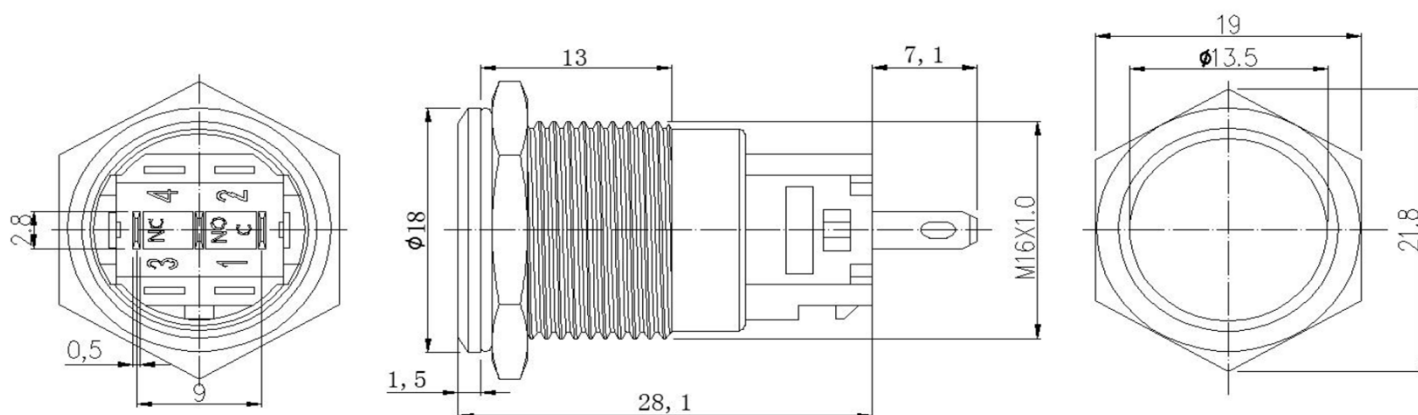

CONNECTION DIAGRAM:

PANEL HOLE:

