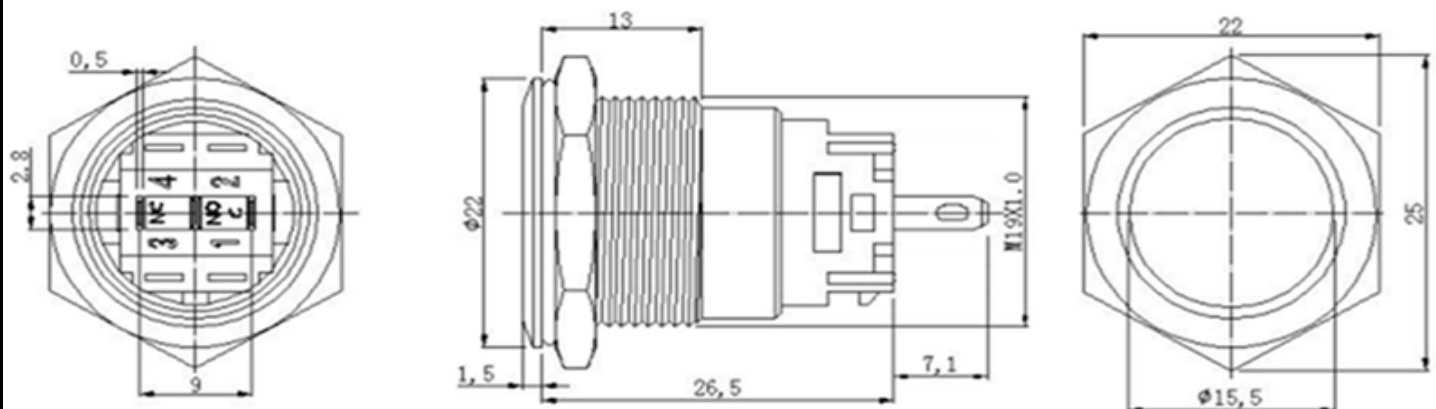


Sales Outline DrawingRevision: **A****Specifications:**

May not be suitable for all Medical and Aerospace applications.
Contact Mallory Sonaalert to discuss your application.

Panel Hole	19 mm
Rated Voltage (VDC / VAC)	36 / 250
Rated Current (A) DC / AC	5 / 5
Switch Function	ON-ON
Circuit	SPDT 1NO1NC
Storage & Operating Temperature	-25 °C to +85 °C
Ingress Protection Rating	IP65
Shock Resistance	IK09
Certifications	UL, cUL listed under Series FLM19-FJ-1
Material, Button	Black aluminum Alloy
Material, Shell	Black aluminum Alloy
Material, Ring	Silica Gel
Material, Nut	H59 Brass
Material, Housing	PA66+GF20%
Termination Type	Solder Lug

Dimensions (mm):**RoHS Compliant****CONNECTION DIAGRAM:****PANEL HOLE:**