

**Sales Outline Drawing**

**Specifications:**

May not be suitable for all Medical and Aerospace applications.  
Contact Mallory Sonalert to discuss your application.

Panel Hole	22 mm
Rated Voltage (VDC / VAC)	36 / 250
Rated Current (A) DC / AC	5 / 5
Switch Function	ON-MOM
Circuit	SPDT 1NO1NC
Storage & Operating Temperature	-25 °C to +85 °C
Ingress Protection Rating	IP67
Shock Resistance	IK08
Certifications	UL, cUL listed under Series FLM12-HJ-1
Material	PC Plastic, PA66+GF20%, Stainless
Termination Type	Solder Lug

**RoHS Compliant**


**Part Number:**

**FWM22-FJ1-S1M3-\***


\* NOTES BUTTON COLOR

- B BLUE
- BL BLACK
- G GREEN
- R RED
- W WHITE
- Y YELLOW
- BLANK CLEAR

**Dimensions (mm):**

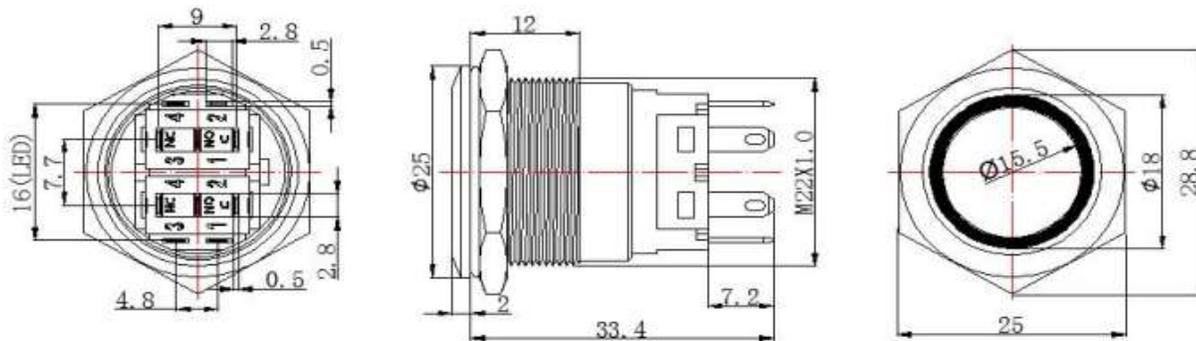

**CONNECTION DIAGRAM:**

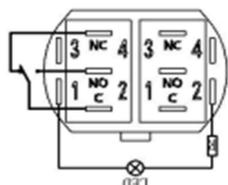

**PANEL HOLE:**

