



Mallory Sonalert Products, Inc.

Part #:

FWM22-FJ6-A0M2

Sales Outline Drawing

Revision:

A




Specifications:

May not be suitable for all Medical and Aerospace applications.
Contact Mallory Sonalert to discuss your application.

Panel Hole	22 mm
Rated Voltage (VDC / VAC)	36 / 250
Rated Current (A) DC / AC	15 / 20
Switch Function	OFF-MOM
Circuit	SPST 1NO
Storage & Operating Temperature	-25 °C to +85 °C
Ingress Protection Rating	IP65
Shock Resistance	IK08
Material, Button	Black aluminum Alloy
Material, Shell	Black aluminum Alloy
Material, Nut	H59 Brass
Material, Housing	PA66+GF20%
Termination Type	Flat Blades-4.8mm

Dimensions (mm):

RoHS Compliant

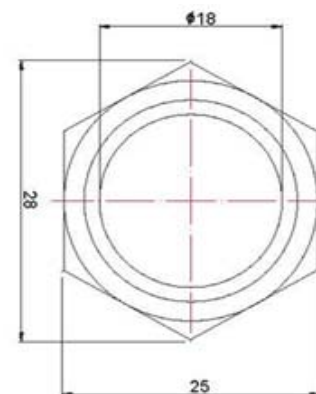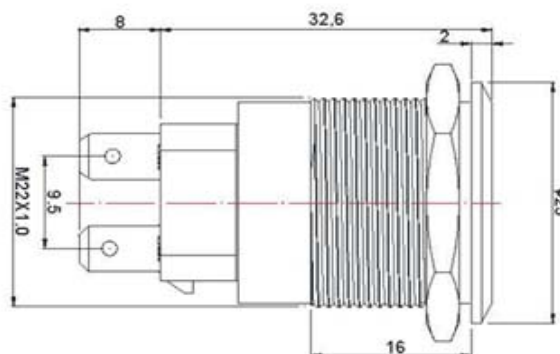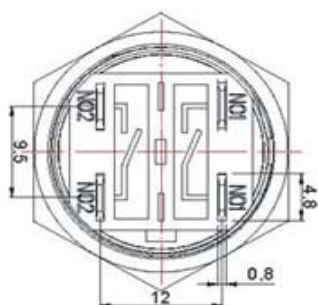

CONNECTION DIAGRAM:

PANEL HOLE:

