

Sales Outline Drawing

Specifications:

May not be suitable for all Medical and Aerospace applications.
Contact Mallory Sonalert to discuss your application.

Panel Hole	19 mm
Rated Voltage (VDC / VAC)	36 / 250
Rated Current (A) DC / AC	5 / 5
Switch Function	OFF-MOM
Circuit	SPST 1NO
Storage & Operating Temperature	-25 °C to +85 °C
Ingress Protection Rating	IP65
Shock Resistance	IK09
Certifications	UL, cUL listed under Series FLM12-HJ-1
Material	PA66+GF20%, Stainless
Termination Type	Wires
Wire Specification	7.3" (185 mm) PVC AWG18

RoHS Compliant


Part Number:

FWPQ19-FW1-S0M2-*


* NOTES BUTTON COLOR

- B BLUE
- BL BLACK
- G GREEN
- R RED
- W WHITE
- Y YELLOW
- BLANK CLEAR

Dimensions (mm):

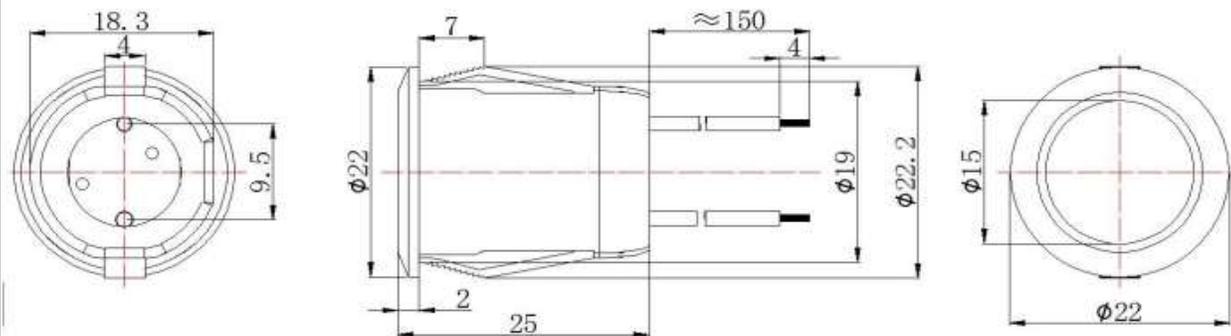

CONNECTION DIAGRAM:

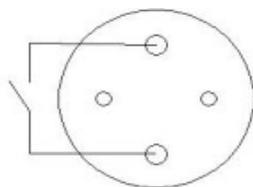

PANEL HOLE:

