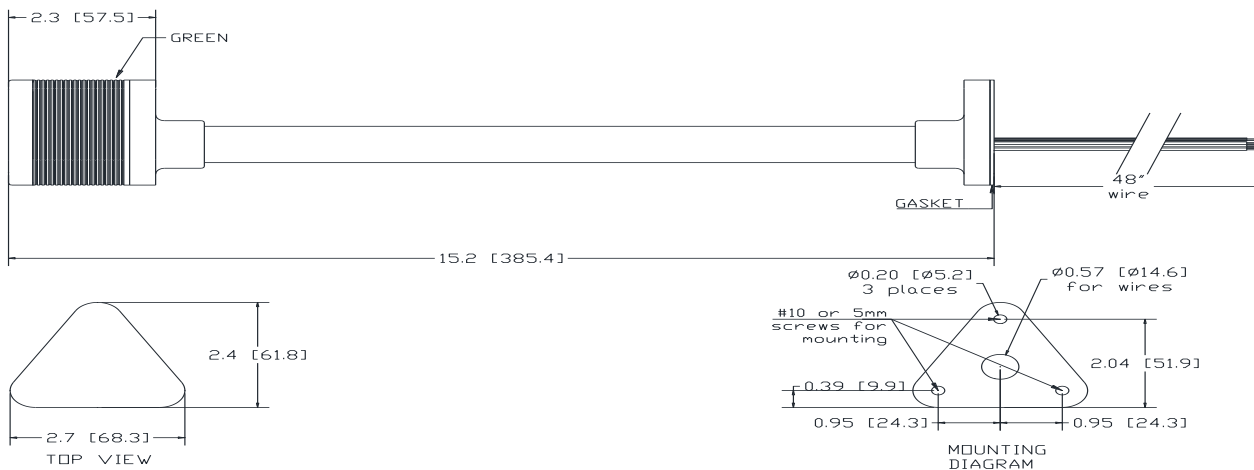


**Mallory Sonalert Products, Inc.**Part #: **JT120-G-CS****Sales Outline Drawing**Revision: **C****Specifications:**

Stack Number:	1				
LED Color:	GREEN				
Connection Wires:	Green and Brown				
LED Current Draw:	<190 mA				
Rated Voltage:	120 VAC				
Operating Voltage:	90-120 VAC				
Total Max Current:	<190mA				
Operating Temperature:	-25° ~ +60°C				
Lens Color:	Opaque White				
Material:	ABS FR15U				
Mounting Method:	Stainless Steel Pole				
Weight Typical (g):	540				
NEMA 12:	Approved				
Options:	Please contact factory.				

Dimensions: Inches (mm)**cUL Recognized****ROHS Compliant**

PATENT NUMBER D898600

**LED OPERATION:** CONNECT STACK COLOR WIRE TO POWER AND BROWN WIRE TO POWER.