

MALLORY Mallory Sonalert Products, Inc.

Part #: **JTC120-RYG-CS**

Sales Outline Drawing

Revision: **A**

Specifications:


Stack Number:	1	2	3		
LED Color:	RED	YELLOW	GREEN		
LED Operation:	Continuous	Continuous	Continuous		
Connection Wires:	Red and Brown	Yellow and Brown	Green and Brown		
LED Current Draw:	<210 mA	<230 mA	<190 mA		
Rated Voltage:			120 VAC		
Operating Voltage:			90-120 VAC		
Total Max Current:			<630mA		
Operating Temperature:			-25° ~ +60°C		
Lens Color:			Transparent - matching LED stack color		
Material:			Lexan CFR7431		
Mounting Method:			Stainless Steel Pole		
Weight Typical (g):			630		
NEMA 12:			Approved		
Options:			Please contact factory.		

Dimensions: Inches (mm)

cUL Recognized

PATENT NUMBER(S) 10309594 D898600

ROHS Compliant

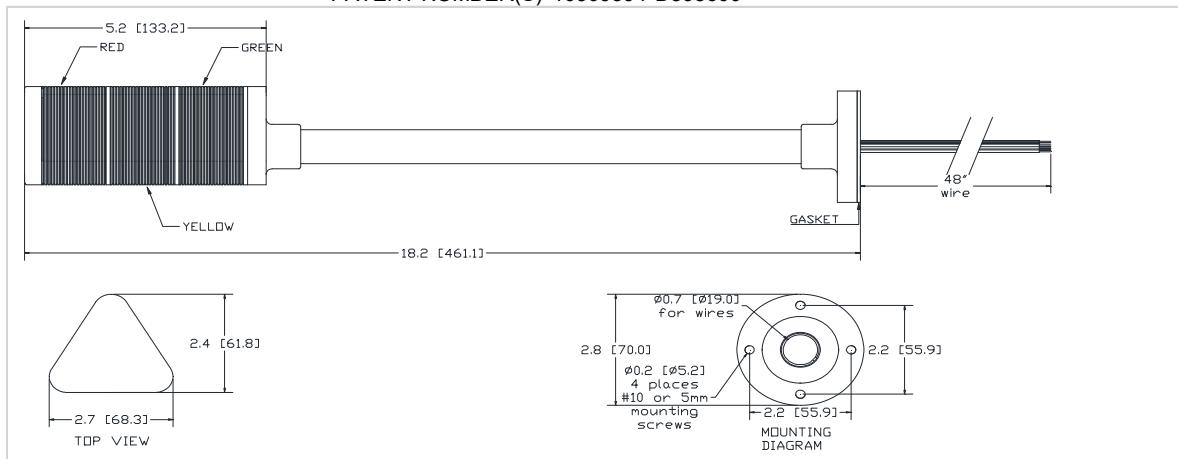

LED OPERATION: CONNECT STACK COLOR WIRE TO POWER AND BROWN WIRE TO POWER.