

**MALLORY** **Mallory Sonalet Products, Inc.**  
**Sales Outline Drawing**

Part #: **JTC120-RG-CD**  
 Revision: **A**

**Specifications:**


Stack Number:	1	2			
LED Color:	RED	GREEN			
LED Operation:	Continuous	Continuous			
Connection Wires:	Red and Brown	Green and Brown			
LED Current Draw:	<210 mA	<190 mA			
Rated Voltage:		120 VAC			
Operating Voltage:		90-120 VAC			
Total Max Current:		<400mA			
Operating Temperature:		-25° ~ +60°C			
Lens Color:		Transparent - matching LED stack color			
Material:		Lexan CFR7431			
Mounting Method:		Direct Mount using 1/2" NPT Stainless Steel Pipe and Nut			
Weight Typical (g):		215			
NEMA 12:		Approved			
Options:		Please contact factory.			

**Dimensions:** Inches (mm)

**cUL Recognized**

**ROHS Compliant**

PATENT NUMBER(S) 10309594 D898600

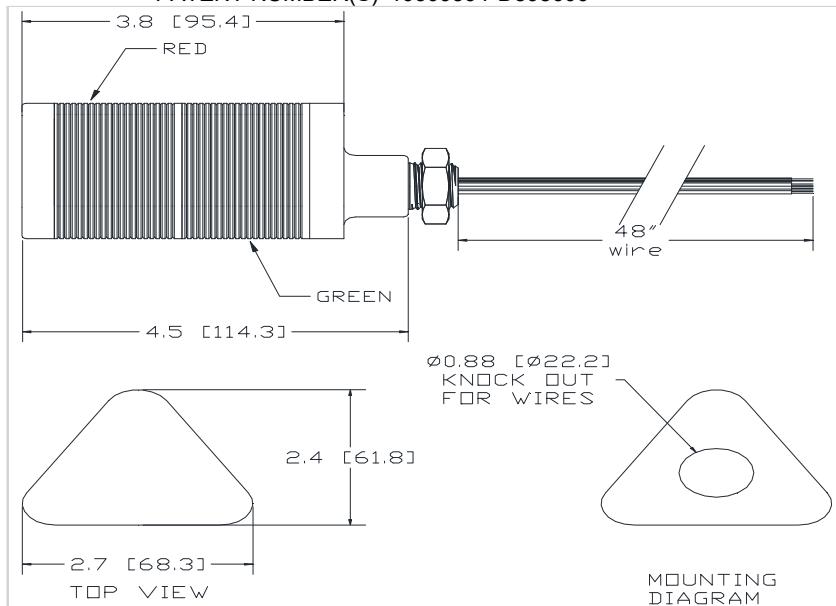

LED OPERATION: CONNECT STACK COLOR WIRE TO POWER AND BROWN WIRE TO POWER.