


May not be suitable for all Medical and Aerospace applications.

Contact Mallory Sonalert to discuss your application.

NO CIRCUITRY

Resonant Frequency (Hz)	2500 \pm 500
Operating Voltage (Vp-p)	3 \sim 28
Rated Voltage (Vp-p)	12
Current Consumption Max. (mA)	10 at Rated Voltage
Sound Pressure Level Min. (dB)	85 at 30cm at Rated Voltage
Operating Temperature (°C)	-20 \sim +90
Storage Temperature (°C)	-30 \sim +100
Housing	ABS 777D UL94HB plastic resin (Color: Black)
Leading Pin	Tin Plated Brass M = Main (Ceramic); F = Feedback; G = Ground (Metal)
Weight (Grams)	4.0
Condition by wave soldering (°C)	260 \pm 5 / 3 \pm 0.5 sec
Condition by hand soldering (°C)	350 \pm 20 / within 5 sec
Options	For other options contact factory

Dimensions: (units: mm)

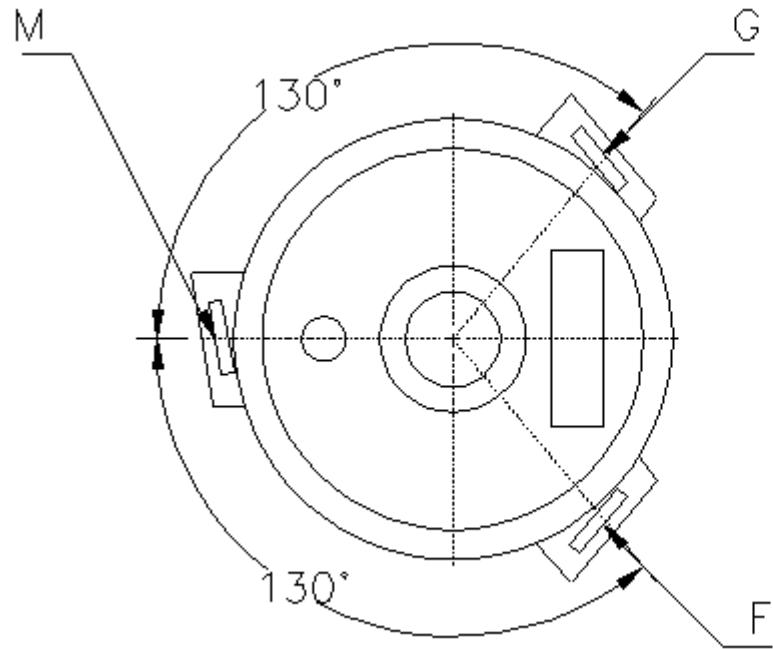

ROHS Compliant

