



Mallory Sonalert Products, Inc.

Part #: **SCE016MD3MV0W**

Sales Outline Drawing

Revision: **B**


Specifications:

Sound Level Category:	Medium	Soft	Soft	Loud
Mode of Operation:	Continuous	Continuous	Continuous	Continuous
Loudness @ 2 FT:	82 dB(A) Typ. @ 12 VDC	60 dB(A) Typ. @ 12 VDC	71 dB(A) Typ. @ 12 VDC	95 dB(A) Typ. @ 12 VDC
Frequency:	2900 $\pm$ 500 Hz	2900 $\pm$ 500 Hz	2900 $\pm$ 500 Hz	2900 $\pm$ 500 Hz
Connection:	RED (+); BLACK (-)	RED (+); BLACK & YELLOW (-)	RED (+); BLACK & BLUE (-)	RED (+); BLACK & YELLOW AND BLUE (-)
Voltage Rating:	6 to 16 VDC			
Current Draw:	40mA MAX			
Housing Material:	6/6 Nylon, Color: Black			
Storage Temperature:	-40° to +85° C			
Operating Temperature:	-40° to +85° C			
Panel Mounting:	Recommended hole size is 1.25"(31.75mm). Thread front will fit standard 30mm(1.181") hole.			
Knurled Nut:	Used to attach part to panel. The max recommended torque is 10 in-lbs.			
Weight (Typical):	1.6 oz (45g)			
NEMA 3R,4X, & 12:	Approved with use of ACC03.			
cUL Recognition:	cUL Recognized			
Options:	Please contact factory.			

Dimensions: Inches (mm)

cUL Recognized

ROHS Compliant

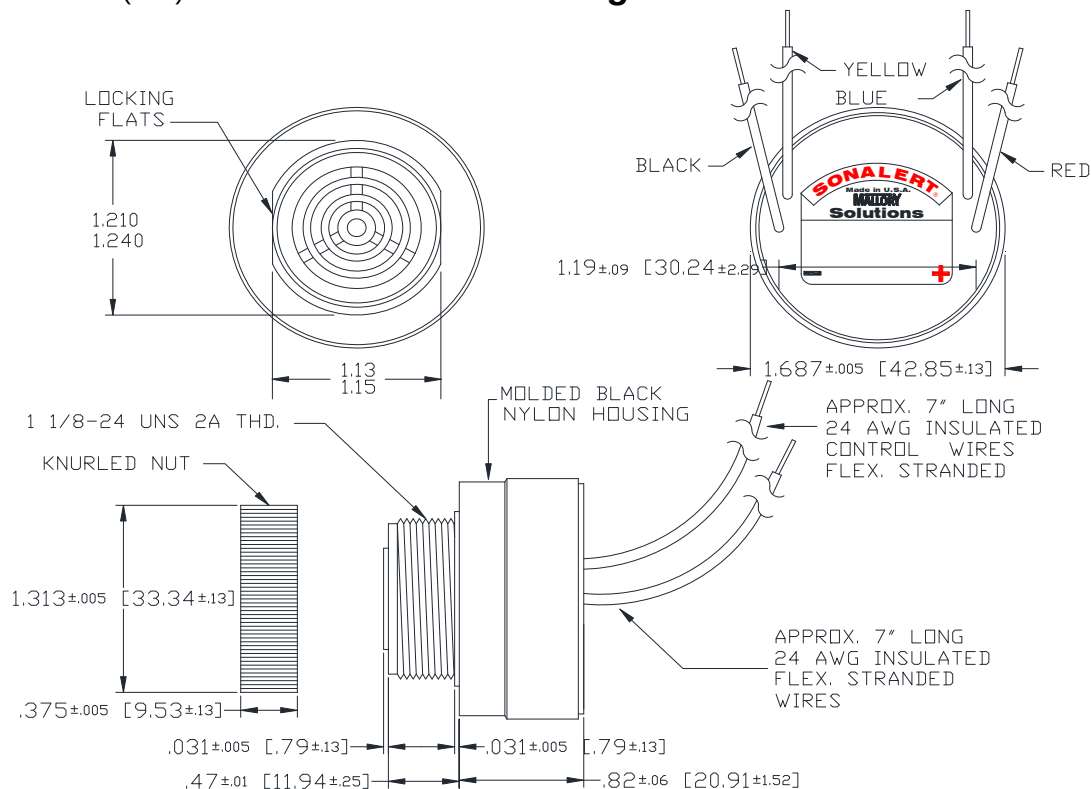

MOUNTING- REMOVE BLACK PLASTIC NUT AND INSERT THREADED FRONT THROUGH 1.25" HOLE PUNCHED IN PANEL, IF ORIENTATION IS NEEDED, NOTE LOCKING FLATS ON DRAWING. SCREW NUT BACK ON. DO NOT OVERTIGHTEN.