


## 16-Device USB Charging Station Cabinet with Sync for iPad and Android Tablets, Wall-Mount and Cart Options, Black

MODEL NUMBER: **CSC16USB**

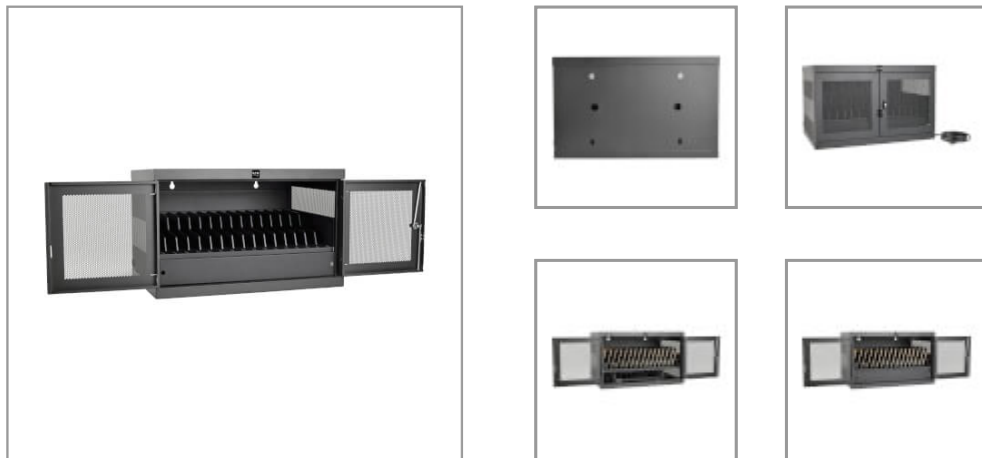

Locking steel cabinet provides 2.4A USB charging, syncing, secure storage and cord management for up to 16 tablets and other devices. Recommended for education, office, commercial, retail, industrial and healthcare environments.

### Features

#### Fast Charging

- 16 USB ports provide fastest charging supported by each device, up to 2.4A per port
- Recommended for iPad, Android, Surface and Kindle tablets
- Also charges mobile phones and other USB devices
- Fits tablets with cases (up to 16.5 x 10.5 x 1.5 in. with cord)
- 10-ft. (3.05 m) AC input cord with NEMA 5-15P plug reaches distant outlets

#### Convenient Syncing

- USB uplink port connects to host computer for wired syncing
- Supports wireless syncing and simultaneous syncing/charging (up to 1.5A per port during wired syncing)

#### Comprehensive Protection

- Sturdy steel construction and powder-coated finish promote long-term durability
- Doors lock with included keys to help prevent device theft, damage or tampering
- 3-point locking mechanism latches doors at top, middle and bottom
- Built-in hasp and user-supplied padlock can replace or supplement built-in lock
- Rear ports accommodate user-supplied bicycle cable or chain lock
- Flow-through ventilation helps prevent devices from overheating
- Protective shelf specially coated to avoid device scratches and scuffs
- Cord access ports with rubber grommets protect against abrasions
- Solid top work surface helps avoid accidental drips and spills that could damage devices

### Highlights

- Fast 2.4A USB charging and syncing for 16 tablets
- Secures devices in locking, vented steel cabinet with cart option
- Protective shelf with removable dividers and cord management
- Supports mounting to wall, desk, table, counter or floor
- Ships fully assembled for quick, easy installation

### Package Includes

- CSC16USB 16-Device USB Charging Station Cabinet, Black
- (2) Keys
- Owner's manual



Powering Business Worldwide

TRIPP LITE  
SERIES

#### Clutter-Reducing Organization

- USB ports and charging cords store out of sight
- Shelf includes charging cord access ports for each device
- Toolless trim panel permits quick access to cords

#### Flexible Configuration

- Ships fully assembled for quick, easy installation
- Supports mounting to wall, desk, table, counter or floor
- Split front doors open 180 degrees for improved device and service access
- Removable dividers accommodate thicker devices like battery chargers
- Firmware upgrade port for future updates
- Converts to mobile cart with optional CSHANDLEKIT2 (sold separately)

## Specifications

| OVERVIEW                           |                          |
|------------------------------------|--------------------------|
| UPC Code                           | 037332194640             |
| Product Type                       | Multi-Device Charger     |
| Charging Form Factor               | Stationary Cabinet       |
| Charger Functions                  | Charge; Secure; Sync     |
| Device Compatibility               | Tablet                   |
| Device Slots                       | 16                       |
| INPUT                              |                          |
| Nominal Input Voltage(s) Supported | 120V AC                  |
| Voltage Compatibility (VAC)        | 110; 120                 |
| Input Frequency                    | 50 / 60 Hz (auto-select) |
| Input Plug Type                    | NEMA 5-15P               |
| Input Cord Length (ft.)            | 10                       |
| Input Cord Length (m)              | 3.05                     |
| OUTPUT                             |                          |
| Frequency Compatibility            | 50 / 60 Hz               |
| POWER                              |                          |
| Power Consumption (Watts)          | 56                       |
| CHARGING                           |                          |
| Number of Charging Ports           | 16                       |
| Total Charging Amps                | 40A                      |



Powering Business Worldwide

TRIPP LITE  
SERIES

|                                      |                          |
|--------------------------------------|--------------------------|
| Total Charging Watts                 | 200                      |
| Charging Method                      | USB                      |
| Charging Port Type                   | USB A (FEMALE)           |
| Charging Ports Details               | Pass through             |
| Charging Ports / Amps                | (16) 2.4A                |
| Overcharge Protection                | Yes                      |
| Charging Amps per Port               | 2.4A                     |
| <b>PHYSICAL</b>                      |                          |
| Color                                | Black                    |
| Material of Construction             | Steel                    |
| Charging Station Form Factor         | Stationary Cabinet       |
| Shipping Dimensions (hwd / in.)      | 24.53 x 23.62 x 33.66    |
| Shipping Dimensions (hwd / cm)       | 62.31 x 59.99 x 85.50    |
| Shipping Weight (lbs.)               | 112.00                   |
| Shipping Weight (kg)                 | 50.80                    |
| Slot Dimensions (hwd / in.)          | 10.6 x 1.5 x 15.4        |
| Slot Dimensions (hwd / mm)           | 268.1 x 38.2 x 390.5     |
| Unit Dimensions (hwd / in.)          | 18.800 x 30.330 x 20.200 |
| Unit Dimensions (hwd / cm)           | 47.75 x 77.04 x 54.86    |
| Unit Weight (lbs.)                   | 84.66                    |
| Unit Weight (kg)                     | 38.40                    |
| Number of Shelves                    | 1                        |
| <b>FEATURES &amp; SPECIFICATIONS</b> |                          |
| Antimicrobial                        | No                       |
| Built-In Circuit Breaker             | Yes                      |
| Cord Management                      | Yes                      |
| Overcurrent Protection               | Yes                      |
| EMI/RFI Line Noise Protection        | Yes                      |
| Flow-Through Ventilation             | Yes                      |
| IP68 Rated                           | No                       |
| IP20 Rated                           | No                       |
| UV Sterilization                     | No                       |
| Locking                              | Yes                      |
| Lock Type                            | Key                      |

|                                     |                                                                    |
|-------------------------------------|--------------------------------------------------------------------|
| STANDARDS & COMPLIANCE              |                                                                    |
| Product Certifications              | NOM (Mexico); UL 60950-1                                           |
| Product Compliance                  | RoHS; CE (Europe); EIA/ECA-310-E; REACH; FCC Part 15 Class B (USA) |
| WARRANTY & SUPPORT                  |                                                                    |
| Product Warranty Period (Worldwide) | 2-year limited warranty                                            |
| CATEGORY PAGE FILTERS (Y/N ONLY)    |                                                                    |
| External Receptacle                 | No                                                                 |

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.