


## Swivel/Tilt Wall Mount with Screen Adjustment for 13" to 27" TVs and Monitors

MODEL NUMBER: DWM1327SP

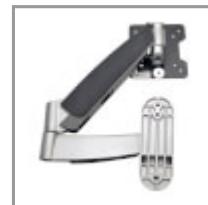

Hangs a flat-panel television, monitor or other display on the wall. Ideal for home, office, hotels, bars and restaurants. Swivels and tilts to provide optimal viewing angles.

### Description

The VESA-compliant DWM1327SP Swivel/Tilt Wall Mount allows you to mount your flat-panel television, monitor or other display on the wall. Ideal for home, office, hotels, bars and restaurants, it fits most flat-panel displays from 13 to 27 inches.

The full-motion swivel arm can be independently adjusted for angle and height to give you maximum flexibility in positioning your display to fit your environment and comfort level. A 180° swivel, -15° to +15° tilt and -2° to +2° screen level adjustment capability minimizes glare and provides comfortable viewing from multiple angles.

Durable all-metal frame with soft rubber-feel finish supports up to 33 lbs (14.9 kgs). Comes fully assembled for quick mounting to the wall with included hardware. Conforms to VESA-compliant displays with any of the following mounting hole patterns: 75 x 75 mm and 100 x 100 mm.

### Features

**Mounts Your TV or Monitor to the Wall** Fits most flat-panel televisions, monitors and other displays from 13 to 27 in. Ideal for home, office, hotels, bars and restaurants. Full-motion swivel arm adjusts independently for angle and height. Mounting hardware included.

**Convenient One-Touch Adjustment** 180° swivel, -15° to +15° tilt and -2° to +2° screen level adjustment capability provides comfortable viewing from multiple angles.

**Durable Metal Construction** Supports up to 33 lbs (14.9 kgs). Soft rubber-feel finish with decorative covers blends with any décor. Fully assembled for immediate installation. Display cable attaches to mount to reduce clutter.

**VESA Compliance** Supports the following VESA mounting hole patterns: 75 x 75 mm, 75 x 100 mm, 100 x 75 mm, and 100 x 100 mm.

## Specifications

### Highlights

- Fits most flat-panel displays from 13 to 27 in.
- One-touch adjustment for comfortable viewing
- 180° swivel, -15° to +15° tilt and -2° to +2° screen adjustment
- Supports up to 33 lbs (14.9 kgs)

### Package Includes

- DWM1327SP Swivel/Tilt Wall Mount for 13" to 27" TVs and Monitors
- (4) M4 screws
- (4) M5 screws
- (4) Washers
- (3) Anchor bolts
- (3) Concrete anchors
- Wrench
- Hex key, 4 mm
- Hex key, 6 mm
- Owner's manual



Powering Business Worldwide

TRIPP LITE  
SERIES

|                                      |  |
|--------------------------------------|--|
| Device Compatibility                 | Monitor/HDTV                                     |
| <b>PHYSICAL</b>                      |  |
| Color                                | Black; Silver                                    |
| Material of Construction             | Steel  |
| VESA Pattern (mm)                    | 100x100; 100x75; 75x100; 75x75                   |
| Motion                               | Full   |
| Mounting Location                    | Wall   |
| Degrees of Motion                    | -15/+15 Tilt; 180 Swivel; -2/+2 Level Adjustment |
| Minimum Screen Size (in.)            | 13   |
| Minimum Screen Size (cm)             | 33.02  |
| Maximum Screen Size (in.)            | 27   |
| Maximum Screen Size (cm)             | 68.58  |
| Maximum Weight Capacity (lbs.)       | 33   |
| Maximum Weight Capacity (kg)         | 15   |
| Min/Max Arm Extension (in.)          | 2.16 min to 22.85 max                            |
| Min/Max Arm Extension (cm)           | 5.49 min to 58.04 max                            |
| Number of Displays                   | 1  |
| Shipping Dimensions (hwd / in.)      | 3.54 x 15.75 x 19.69                             |
| Shipping Dimensions (hwd / cm)       | 8.99 x 40.00 x 50.01                             |
| Shipping Weight (lbs.)               | 8.64   |
| Shipping Weight (kg)                 | 3.92   |
| Unit Dimensions (hwd / in.)          | 7.480 x 5.200 x 22.830                           |
| Unit Dimensions (hwd / cm)           | 19 x 47.5 x 13.2                                 |
| Unit Weight (lbs.)                   | 8.64   |
| Unit Weight (kg)                     | 3.92   |
| <b>FEATURES &amp; SPECIFICATIONS</b> |  |
| Antimicrobial                        | No   |
| Cord Management                      | No   |
| Tools Necessary                      | Yes  |
| Security Lock                        | No   |
| <b>STANDARDS &amp; COMPLIANCE</b>    |  |
| Product Compliance                   | RoHS; RoHS3; REACH                               |
| <b>WARRANTY &amp; SUPPORT</b>        |  |



*Powering Business Worldwide*

TRIPP LITE  
SERIES

|                                     |                         |
|-------------------------------------|-------------------------|
| Product Warranty Period (Worldwide) | 5-year limited warranty |
|-------------------------------------|-------------------------|

1000 Eaton Boulevard

Cleveland, OH 44122

United States

<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.

Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.