


Power Cable Kit for Healthcare Power Modules/Inverters/Chargers, 3 ft. (0.91 m)

MODEL NUMBER: HCBATTERYCABLE

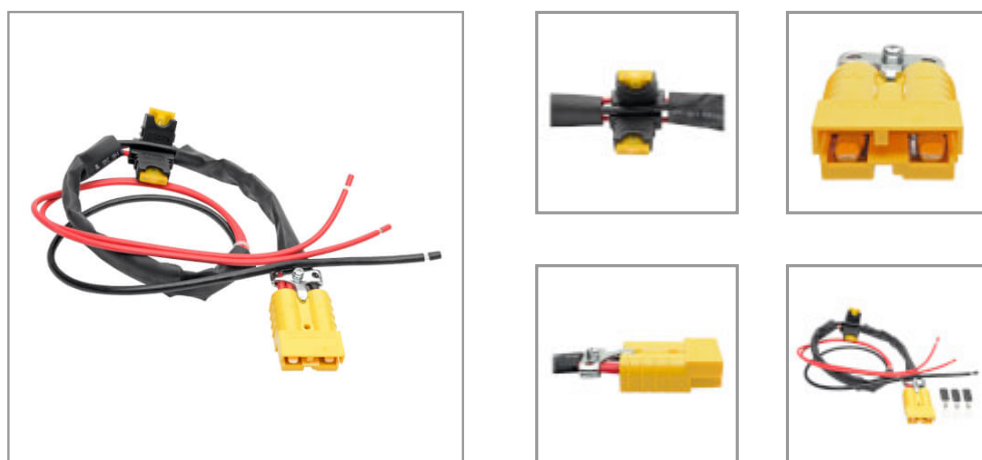

Power cable kit connects a battery to a medical power module mounted on a mobile medical cart in a healthcare facility.

Features

Power Cable Kit Connects a Battery to Your Medical Power Module

This cable is designed to work with medical power modules, including HC150SL, HCINT150SL, HC350SNR, HC350SR and HCINT350SNR. It includes a quick-release Anderson plug for easy connection to the power inverter/charger and three ring terminals for connecting to a Sealed Lead Acid (SLA) or Lithium Iron Phosphate (LiFePhos) battery. The wires (two 12 AWG red and one 10 AWG black) are three feet in length, but can be cut to a customized length to properly fit your application. Two user-replaceable 20-amp fuses are also included. This power cable kit accommodates 12VDC batteries up to 55Ah.

Highlights

- Designed to work with select medical power modules
- Accepts 12VDC SLA or LiFePhos battery packs up to 55Ah
- Quick-release Anderson plug connects easily to power inverter/charger
- 3 ft. (0.91 m) cables can be easily cut to customized length and fitted with included ring terminals
- Includes 2 user-replaceable 20A fuses for immediate deployment

Applications

- Supply battery power to a Tripp Lite power module connected to a mobile medical cart in a hospital or other healthcare facility

System Requirements

- HC150SL, HCINT150SL, HC350SNR, HC350SR, HCINT350SNR and other compatible power modules

Package Includes

- HCBATTERYCABLE Power Cable Kit, 3 ft.

Specifications

OVERVIEW	
UPC Code	037332168771
Accessory Type	Cable Kit
Country/Region	Global
Accessory Class	UPS Accessories
PHYSICAL	
Color	Black; Red; Yellow
Cable Jacket Color	Black; Red; Yellow
Power Cord Jacket Type	Null
Number of Conductors	0
Cable Length (ft.)	3



Powering Business Worldwide

TRIPP LITE
SERIES

Cable Length (m)	0.91
Cable Length (in.)	36
Cable Length (cm)	914.4
Shipping Dimensions (hwd / in.)	1.00 x 2.50 x 3.50
Shipping Weight (kg)	0.25
FEATURES & SPECIFICATIONS	
High Voltage	No
Locking Plug	No
STANDARDS & COMPLIANCE	
Product Compliance	RoHS
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	Lifetime limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.