


Center Plate Insert, Decora Style - Vertical, 2 Ports, TAA

MODEL NUMBER: **N042D-002V-WH**

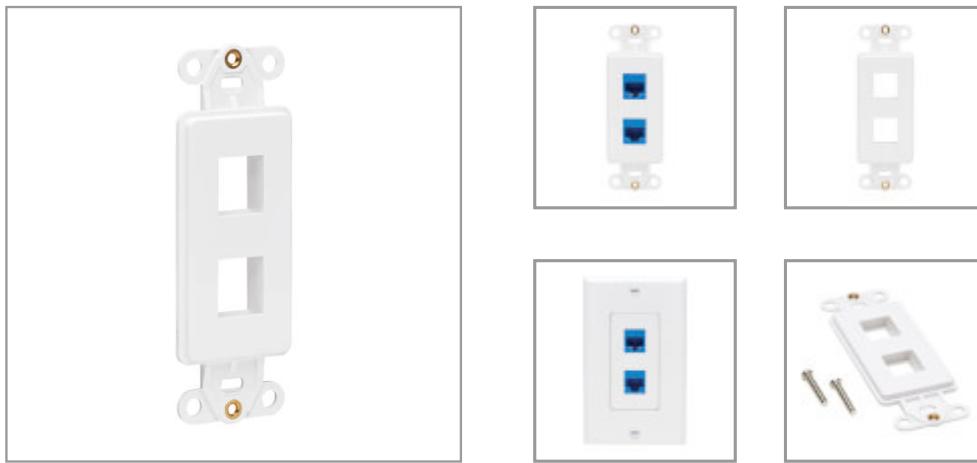

Clean, simple insert mounts within Decora-style wall plate for terminating in-wall audio/video, voice or Ethernet cable installations.

Features

Decora-Style Face Plate Connects Audio/Video, Voice and Data Cable Lines at the Wall This vertical-style center insert provides a clean, simple method for your premise wiring applications, including home theater (audio/video), VoIP phones (voice) and Ethernet (data). Any type of keystone jack, including those used in HDMI, DisplayPort, RCA, USB and Cat5e/6/6a installations, snaps easily into the cutouts for quick cable connection.

High-Impact Construction Designed to Blend In Seamlessly The Decora-style polycarbonate insert plate is white and blends elegantly into any home or office décor for a sleek, professional installation. Mounting screws are included for flush mounting the insert with a compatible Decora-style wall plate (sold separately).

Specifications

OVERVIEW	
UPC Code	037332249708
Technology	Cat5/5e; Cat6; Cat6a; DisplayPort; HDBaseT; HDMI; USB 2.0 (High Speed)
Country/Region	Global
CONNECTIONS	
Number of Ports	2
Side A - Connector 1	KEYSTONE JACK CUTOUT
Side B - Connector 1	KEYSTONE JACK CUTOUT
PHYSICAL	

Highlights

- Ideal for home theater, VoIP or Ethernet premise wiring installations
- Compatible with any type of keystone jack, including HDMI, Cat5/6, USB and DisplayPort
- High-impact polycarbonate construction designed to last long in your décor
- Hardware included for mounting flush with compatible Decora-style wall plate

Applications

- Complete your premise wiring application with a clean, sleek-looking Decora-style appearance

Package Includes

- N042D-002V-WH Center Plate Insert, Decora Style - Vertical, 2 Ports
- (2) Mounting screws



Powering Business Worldwide

TRIPP LITE
SERIES

Color	White
Material of Construction	ABS
Total Number of Ports	2
ENVIRONMENTAL	
Operating Temperature Range	14° to 140°F (-10° to 60°C)
Storage Temperature Range	-40° to 154°F (-40° to 68°C)
Relative Humidity	10% to 90% (Non-Condensing)
FEATURES & SPECIFICATIONS	
Antibacterial	No
STANDARDS & COMPLIANCE	
Product Compliance	RoHS; REACH; Trade Agreements Act (TAA)
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	Lifetime limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.