


12-Port 1U Rack-Mount Unshielded Blank Keystone/Multimedia Patch Panel, RJ45 Ethernet, USB, HDMI, Cat5e/6

MODEL NUMBER: N062-012-KJ

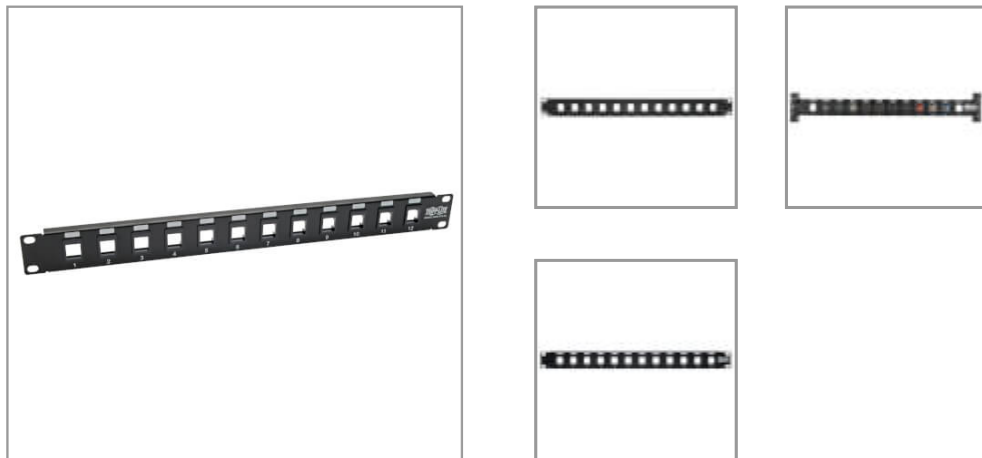

Manages and organizes input and output cable connections in your network. Customizable solution for a variety of applications, including Ethernet, voice, audio/video and USB.

Description

The N062-012-KJ 12-Port 1U Rack-Mount Unshielded Blank Keystone/Multimedia Patch Panel manages and organizes the cabling in your network. The 12 blank cutouts accommodate all keystone jacks, including RJ45 Ethernet, HDMI audio/video, voice and USB applications. Ports are clearly numbered to help you identify connections. Mounts easily into 1U of an EIA-standard 19-inch two-post rack or wall-mount rack enclosure. Made from heavy-duty cold-rolled steel. Grounding wire included.

Features

Manages and Organizes a Wide Variety of Cabling 12 blank cutouts accommodate most keystone jacks in the market
For use with RJ45 Ethernet, HDMI audio/video, voice, USB and other applications
Ports are numbered for easy connection identification
Heavy-duty cold-rolled steel construction

Quick, Easy Installation Mounts easily into 1U of EIA-standard 19 in. 2-post rack or wall-mount rack enclosure
Includes grounding wire

Highlights

- 12 blank cutouts compatible with all keystone jacks
- For Ethernet, voice, audio/video, USB applications and more
- Heavy-duty cold-rolled steel construction
- Numbered ports for easy connection identification
- Mounts into 1U of standard 19 in. 2-post or wall-mount rack

Package Includes

- N062-012-KJ 12-Port 1U Rack-Mount Unshielded Blank Keystone/Multimedia Patch Panel
- Grounding wire

Specifications

OVERVIEW	
UPC Code	037332193551
Product Type	Rackmount
Technology	Cat5/5e; Cat6; Cat6a; DisplayPort; HDMI; USB 2.0 (High Speed)
CONNECTIONS	
Number of Ports	12
Side A - Connector 1	KEYSTONE JACK CUTOUT



Powering Business Worldwide

TRIPP LITE
SERIES

Side B - Connector 1	KEYSTONE JACK CUTOUT
PHYSICAL	
Color	Black
Shipping Dimensions (hwd / in.)	0.67 x 1.85 x 19.61
Shipping Dimensions (hwd / cm)	1.70 x 4.70 x 49.81
Shipping Weight (lbs.)	0.80
Shipping Weight (kg)	0.36
Panel Style	Blank
FEATURES & SPECIFICATIONS	
IP68 Rated	No
IP20 Rated	No
STANDARDS & COMPLIANCE	
Product Compliance	RoHS
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	Lifetime limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.