


Important Note

Guaranteed compatibility when used with recommended cabling. Designed specifically for use with N842-, N844- and N845-Series cables.

40 GB Pass-Through Cassette, (x12) 12-Fiber MTP/MPO (Female)

MODEL NUMBER: **N482-12M12-X2**

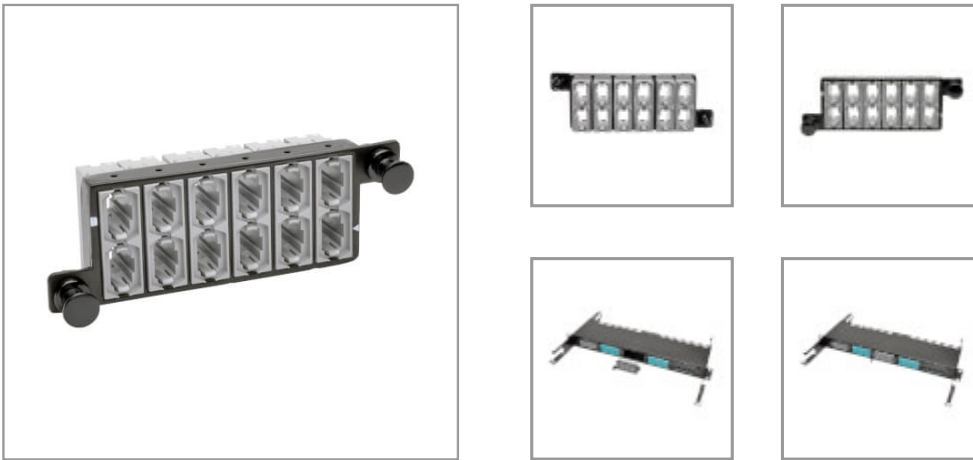

Installs in select Tripp Lite fiber enclosure panels to create up to twelve 40 GB 12-fiber MTP/MPO connections in high-density network applications.

Description

The N482-12M12-X2 40 GB Pass-Through Cassette works in tandem with N482-01U or N482-02U Fiber Enclosure Panels to create up to twelve 12-fiber MTP/MPO connections in high-density network applications.

The cassette's modular design installs easily in the N482-01U and N482-02U enclosure panels with no tools required. Just insert the cassette into the panel, and push in its retention clips to secure it. Plug 40 GB 12-fiber MTP/MPO Ethernet cables into the cassette to connect up to 12 network feeds. Up to five N482-12M12-X2 cassettes fit in the N482-01U 1U enclosure panel for a total of 60 network feeds, and up to 14 cassettes fit in the N482-02U 2U panel for a total of 168 network feeds. Guaranteed compatibility when used with recommended cabling, such as the N842-, N844- and N845- Series.

With a heavy-duty steel housing and factory-terminated connectors that reduce time and labor, the N482-12M12-X2 is made from only the finest materials to ensure fast installations and optimal performance.

Features

Elegant, Simple Solution for 40 GB 12-Fiber MTP/MPO Connections

- High-density fiber cassette for use with N482-01U and N482-02U fiber enclosure panels
- Connect up to twelve 40 GB 12-fiber MTP/MPO cables
- Guaranteed compatibility when used with recommended cabling
- Designed specifically for use with cables, such as the N842-, N844- and N845- Series cables

Simple Fiber Installations Save Time and Money

- Push/pull retention clips for easy installation with no tools required
- Install up to 5 in N482-01U 1U enclosure panel for up to 60 network feeds total
- Install up to 14 in N482-02U 2U enclosure panel for up to 168 network feeds total

Highlights

- For use with N482-01U or N482-02U enclosure panels
- Connect up to twelve 40 GB 12-fiber MTP/MPO cables
- Guaranteed compatibility when used with recommended cabling
- Designed specifically for use with cables, such as the N842-, N844- and N845- Series cables
- Simple installation with no tools required
- Factory-terminated connectors
- Heavy-duty steel housing

System Requirements

- Guaranteed compatibility when used with recommended cabling
- Designed specifically for use with N842-, N844- and N845- Series cables

Package Includes

- 40 GB Pass-Through Cassette, (x12) 12-Fiber MTP/MPO
- Quick Start Guide



Powering Business Worldwide

TRIPP LITE
SERIES

Premium Construction for Optimal Performance

- Heavy-duty steel construction
- Factory-terminated connectors reduce time and labor

Specifications

OVERVIEW	
UPC Code	037332191359
Technology	Multimode
CONNECTIONS	
Number of Ports	12
Side A - Connector 1	12F MTP/MPO (FEMALE)
Side B - Connector 1	12F MTP/MPO (FEMALE)
PHYSICAL	
Shipping Dimensions (hwd / in.)	2.40 x 3.90 x 2.40
Shipping Dimensions (hwd / cm)	6.10 x 9.91 x 6.10
Shipping Weight (lbs.)	0.20
Shipping Weight (kg)	0.09
STANDARDS & COMPLIANCE	
Product Compliance	RoHS
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	Lifetime limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.