


VGA with Audio to HDMI Converter with Scaler Function

MODEL NUMBER: **P116-000-HDSC1**

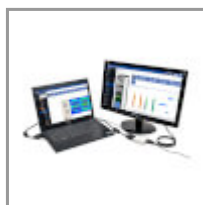

Converts and upscales analog VGA video for display on an HDMI projector, monitor or television without having to upgrade your source equipment.

Features

Save Money on Costly Computer Upgrades to Video Source Equipment

The P116-000-HDSC1 VGA converts and upscales a VGA video signal for viewing on an HDMI display. The built-in scaler upgrades the VGA input signal, allowing you to display 720p or 1080p high-definition video in your audio/video setup, media presentation or digital signage using your tried-and-true analog source equipment. The media converter is ready to use right from the box with no software installations required.

Upscales Analog Video to 1080p

Connect the VGA video and 3.5 mm mini-stereo audio ports to your computer and the HDMI port to your HDMI projector, monitor or television with user-supplied cables. The P116-000-HDSC1 automatically upscales the video signal to 720p. Toggle the display to 1080p by pressing the button on the unit. The converter supports computer input video resolutions up to 1920 x 1440 at 60 Hz. It also supports HDMI bandwidth of 165 MHz (1.65 Gbps per channel) and 24-bit True Color (8 bits per channel).

Highlights

- Built-in scaler converts and upgrades VGA signal to 1080p HDMI
- Supports computer input video resolutions up to 1920 x 1440 @ 60 Hz
- Eliminates costly upgrades to your analog source devices
- Included power supply comes with 4 international plug adapters
- Plug-and-play operation with no software required for easy, immediate installation

System Requirements

- Source with VGA video port and 3.5 mm mini-stereo audio port
- Display with HDMI port

Package Includes

- P116-000-HDSC1 VGA with Audio to HDMI Converter
- External power supply (Input: 100–240V, 50/60 Hz, 0.3A; Output: 5V 1A)
- (4) International plug adapters (North America, Europe, United Kingdom, Australia)
- Owner's manual

Specifications

OVERVIEW	
UPC Code	037332188335
Product Type	Video Adapter
Device Compatibility	Monitor/HDTV
Technology	HDMI; Stereo Audio; VGA/SVGA
POWER	
AC Adapter	Input: 100-240V, 50/60Hz, 0.5A; Output: 5V, 2A, 4 ft.



Powering Business Worldwide

TRIPP LITE
SERIES

CONNECTIONS	
Side A - Connector 1	HD15 (FEMALE)
Side A - Connector 2	3.5MM (FEMALE)
Side B - Connector 1	HDMI (FEMALE)
PHYSICAL	
Color	White
Shipping Dimensions (hwd / in.)	2.20 x 4.60 x 6.70
Shipping Dimensions (hwd / cm)	5.59 x 11.68 x 17.02
Shipping Weight (lbs.)	0.80
Shipping Weight (kg)	0.36
Unit Dimensions (hwd / in.)	0.000 x 0.000 x 0.000
Unit Dimensions (hwd / cm)	2 x 5.6 x 6.1
Unit Weight (lbs.)	0.1
Unit Weight (kg)	0.05
ENVIRONMENTAL	
Operating Temperature Range	32° to 158°F (0° to 70°C)
Storage Temperature Range	14° to 176°F (-10° to 80°C)
Operating Humidity Range	10 to 85% RH, Non-Condensing
Storage Humidity Range	5 to 95% RH, Non-Condensing
STANDARDS & COMPLIANCE	
Product Certifications	EN 55024
Product Compliance	RoHS
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	2-year limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.