


SmartRack Cable Gland Plate for NEMA-Rated Enclosure Cabinets, 6 Ports (0.5 in.)

MODEL NUMBER: **SRGP1KO**

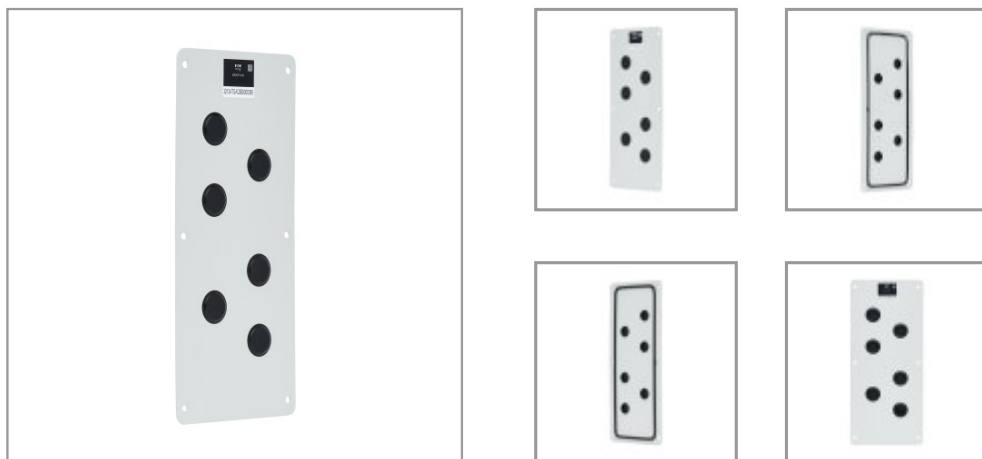

Cable entry plate covers entry/exit cable cutouts on SmartRack NEMA 3R and NEMA 4 industrial enclosures.

Features

Gasketed Cable Entry Plate for NEMA-Rated Industrial Enclosures

This metal-reinforced gland plate covers cable entry and exit cutouts on SmartRack® NEMA 3R and NEMA 4 industrial enclosures, including the SRN and SRIN series. The SRGP1KO is sized to correspond to the enclosures' cable cutouts, making it quick and easy to install. Six half-inch (12 mm) ports accept user-supplied cable fittings or conduit. LDPE escutcheons protect unused ports against dust and moisture to protect the enclosure's NEMA 3R or NEMA 4 rating.

Highlights

- Rugged gasketed cable gland plate with metal reinforcement for long life
- Features 6 half-inch (12 mm) ports for installing cable fittings or conduit
- Screw mounting maintains NEMA rating of SmartRack industrial enclosure
- Polyethylene (LDPE) escutcheons protect unused ports against dust and moisture

System Requirements

SmartRack NEMA 3R and NEMA 4 industrial enclosures

Package Includes

- SRGP1KO Cable Entry Plate
- (6) M5 screws
- Owner's manual

Specifications

OVERVIEW	
UPC Code	037332262882
Accessory Type	Gland Plate
Accessory Class	Rack Accessories
PHYSICAL	
Total Number of Ports	6
Shipping Dimensions (hwd / in.)	1.43 x 8.31 x 15.81
Shipping Dimensions (hwd / cm)	3.65 x 21.12 x 40.17
Shipping Weight (lbs.)	1.60
Shipping Weight (kg)	0.73
Unit Dimensions (hwd / in.)	0.300 x 13.386 x 5.906
Unit Dimensions (hwd / cm)	0.76 x 34 x 15



Powering Business Worldwide

TRIPP LITE
SERIES

Unit Weight (lbs.)	1.00
Unit Weight (kg)	0.45
FEATURES & SPECIFICATIONS	
IP68 Rated	No
IP20 Rated	No
STANDARDS & COMPLIANCE	
Product Compliance	REACH; RoHS
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	2-year limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.