


## 4-Port USB-C Hub, USB 3.x (5Gbps), 2x USB-A, 2x USB-C, White

MODEL NUMBER: **U460-004-2A2C**

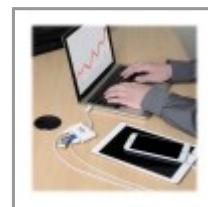

Adds USB-A and USB-C ports to the USB-C or Thunderbolt 3 port on your tablet, laptop, notebook, MacBook, Chromebook, smartphone or PC.

### Description

The U460-004-2A2C USB 3.1 Gen 1 USB-C Portable Hub expands the potential of your tablet, laptop, MacBook, Chromebook, smartphone or PC's USB-C or Thunderbolt 3 port. It's ideal for adding a thumb drive and other USB peripherals and charging a mobile device—all at the same time.

The plug-and-play U460-004-2A2C requires no software, drivers or external power. Connect the reversible USB-C plug to your source device's USB-C or Thunderbolt 3 port. The fumble-free USB-C plug connects in either direction to ensure fast, easy connection every time.

Dual USB-A ports accept USB peripherals, such as a flash drive, mouse, keyboard or printer, and provide up to 0.9A each for charging smartphones and other mobile devices. They support fast USB 3.1 Gen 1 data transfer rates up to 5 Gbps and are backward compatible with previous USB generations, so you can continue using older peripherals while getting high-speed performance from new devices.

Dual USB-C ports also connect to a wide range of USB devices, including external hard drives and tablets. Each provides up to 1.5A of charging power. They also support USB 3.1 Gen 1 data transfer rates up to 5 Gbps and are backward compatible with previous USB generations.

### Features

**Turn Your Device's USB-C Port into a Multiport Workstation** Ideal for adding USB peripherals and charging mobile devices simultaneously. Plug-and-play operation with no software, drivers or external power required. About the size of a credit card for easy carrying in a pocket, purse or laptop bag.

**Connect USB Peripherals** 2 USB-A ports provide up to 0.9A each for charging devices. 2 USB-C ports provide up to 1.5A each for charging devices. Supports USB 3.1 Gen 1 data transfer rates up to 5 Gbps. Backward compatible with USB 2.0 and USB 1.1.

Note: Host must support USB OTG (On-the-Go)

**Built-In Cable with Reversible USB-C Connector** Fumble-free reversible USB-C plug connects in either direction for quick connection every time.

## Specifications

### OVERVIEW

### Highlights

- Supports USB 3.1 Gen 1 data transfer rates up to 5 Gbps
- USB-C ports provide up to 1.5A each for charging devices
- USB-A ports provide up to 0.9A each for charging devices
- Reversible USB-C plug connects in either direction
- Plug-and-play operation with no software or drivers required

### System Requirements

- Source device with USB-C or Thunderbolt 3 port

### Package Includes

- U460-004-2A2C USB 3.1 Gen 1 USB-C Portable Hub
- Owner's manual



Powering Business Worldwide

TRIPP LITE  
SERIES

UPC Code	037332200785
Product Type	Hub
Technology	USB 3.x
Host Connector	USB C (MALE)
<b>VIDEO</b>	
Number of Monitors Supported	0
Extended Mode	No
Mirror Mode	No
DisplayPort Alt Mode	No
<b>DATA</b>	
Data Ports	(2) USB A (FEMALE); (2) USB C (FEMALE)
Data Ports Details	(2) USB-A - USB 3.2 Gen 1 (5 Gbps); (2) USB-C - USB 3.2 Gen 1 (5 Gbps)
<b>INPUT</b>	
Bus Powered	Yes
Product Length (in.)	6
Product Length (cm.)	15.24
Product Length (ft.)	0.5
Product Length (m)	0.15
<b>BATTERY</b>	
Battery Charging (5V/1.5A Port)	Yes
<b>POWER</b>	
Power Consumption (Watts)	2.5
<b>CONNECTIONS</b>	
Number of Ports	4
Side A - Connector 1	USB C (MALE)
Side B - Connector 1	(2) USB 3.0 A (FEMALE)
Side B - Connector 2	(2) USB C (FEMALE)
Connector Plating	Nickel
<b>CHARGING</b>	
Charging Ports / Amps	(2) 0.9A; (2) 1.5A
<b>PHYSICAL</b>	



Powering Business Worldwide

TRIPP LITE  
SERIES

Color	White
Material of Construction	Plastic
Cable Jacket Rating	VW-1
Shipping Dimensions (hwd / in.)	0.80 x 3.90 x 4.60
Shipping Weight (lbs.)	0.20
Unit Dimensions (hwd / in.)	0.000 x 0.000 x 0.000
Unit Packaging Type	Box
Unit Weight (lbs.)	0.07
Unit Weight (kg)	0.03
<b>ENVIRONMENTAL</b>	
Operating Temperature Range	32° to 113°F (0° to 45°C)
Storage Temperature Range	14° to 158°F (-10° to 70°C)
Relative Humidity	5% to 90% RH, Non-Condensing
BTUs	8.5
<b>FEATURES &amp; SPECIFICATIONS</b>	
USB Hub Ports	Yes
Number of USB Hub Ports	4
USB Specification	USB 3.0 (up to 5 Gbps); USB 3.1 Gen 1 (up to 5 Gbps); USB 3.2 Gen 1 (up to 5 Gbps)
UASP Support	Yes
Auto MDIX Support	No
Full Duplex Support	No
Suspend Mode Support	No
Remote Wakeup Support	No
Driver Required	No
<b>STANDARDS &amp; COMPLIANCE</b>	
TAA Compliant Option	N
Product Compliance	RoHS; CE (Europe); REACH; FCC (USA)
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	3-year limited warranty



*Powering Business Worldwide*

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

TRIPP LITE  
SERIES

© 2024 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.