




Quality Products. Service Excellence.


Low Profile Audio 141 Series

PC Board Mount

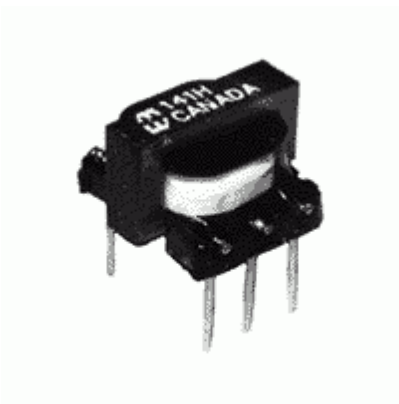

Features

- Pin type (0.25" length & 0.035" diameter), P.C. board mount
- Low profile, open type construction
- Frequency response 200 Hz. - 50 Khz. (+/- 1 db, ref. @ 1 Khz.)
- Net weight 0.6 oz.

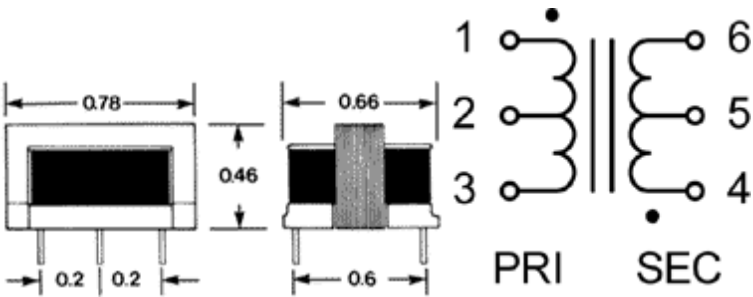

Part No.	Nominal Impedance (Ohms)		Max. Pri. D.C. current (ma.)	D.C. Resistance (Ohms)		Output (Milliwatts)
	Primary	Secondary		Primary	Secondary	
141B	200 K	1000	0	3775	85	4
141D	3000 ct	1000 ct	1	120	51	150
141F	25 K	50	2	1645	65	100
141H	600 ct	600 ct	2	32	45	150
141M	30 K	1200 ct	2	1100	47	100
141P	1200 ct	8	2	50	0.45	150

Note: Part number 141M is incorrectly listed as having a 300K primary impedance in our latest catalogs, the primary is actually 30K as shown above.

Tags: audio transformer, low profile, board mount, PCB mount

Data subject to change without notice

© 2025. Hammond Manufacturing Ltd. All rights reserved.