




Quality Products. Service Excellence.

Type 4X Stainless Steel Two Door Floormount Enclosure 1422 N4 SS

Series

Continuous Hinge Door with Clamps

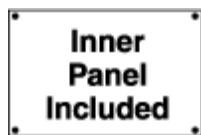

Application

- Designed to house electrical, electronic, hydraulic or pneumatic controls and instruments
- Provides protection where equipment may be hosed down or otherwise be very wet, or in specific applications where corrosion is a serious problem.

Standards

- UL 508A Type 3R, 4, 4X, and 12
- CSA Type 3R, 4, 4X, and 12
- Complies with
 - NEMA Type 3R, 4, 4X, 12 and 13
 - IEC 60529, IP66

Construction

- Formed 12 gauge 304 or 316 stainless steel.
- Smooth, continuously welded seams without knockouts, cutouts or holes.
- Body stiffeners are provided in the larger enclosures for extra rigidity.
- Heavy duty stainless steel lifting eyebolts are provided with reinforcing support angles.
- Center post is removable for easy installation of the inner panel.
- Formed lip on door and top of enclosure opening exclude flowing liquids and contaminants.
- Continuously hinged doors may be removed by pulling the stainless steel hinge pin.
- Doors are secured with heavy duty stainless steel clamps.
- Provision for padlocking.
- 12" floor stands are welded to the enclosure.
- Seamless poured-in place gasket.
- Panel supports are provided for easy panel installation.
- Collar studs are provided for mounting inner panels.
- A bonding stud is provided on the door and a grounding stud is provided in the enclosure for each door.
- A literature pocket is provided.

Finish

- Cover and enclosure are natural stainless steel with a smooth brushed finish.
- Removable 10 gauge inner panel is finished in white powder coating.

Accessories

• Additional Inner Panels	• Door Stop Kit
• Barrier Kits for Type 4 Floormount	• Drip Shield Kit
• Door Clamping Hardware	• Wallmount Quick Release Clamp
• Window Kits	• Climate Control
• Lighting	• General Accessories

**New and improved PDF part
drawing files with more detail
now available.**

Click part number in table below
to access PDF, DXF, and STEP files.

304 S.S.	316 S.S.	Enclosure			Panel	
Part No.	Part No.	H	W	D	H	W
1422N4SSB12F	1422N4S16B12F	60.13	48.06	12.69	56.00	44.00
1422N4SSD12F	1422N4S16D12F	60.13	60.06	12.69	56.00	56.00
1422N4SSE12F	1422N4S16E12F	72.13	60.06	12.69	68.00	56.00
1422N4SSF12F	1422N4S16F12F	72.13	72.06	12.69	68.00	68.00
1422N4SSF24F	1422N4S16F24F	72.13	72.06	24.69	68.00	68.00

Tags: **1422, floormount, two door, stainless steel, Type 4X, NEMA 4X, instrument, hydraulic, pneumatic, 304, 316, continuous hinge, clamps**

Data subject to change without notice

© 2026. Hammond Manufacturing Ltd. All rights reserved.