



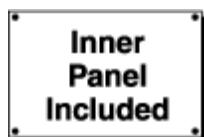

Quality Products. Service Excellence.

## Type 12 Modular Console Cabinet 1472 Series

Sloped Front

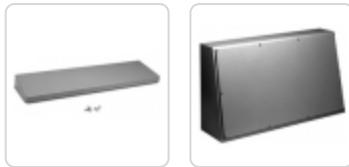

### Application

- Designed to house electrical, electronic, hydraulic or pneumatic controls and instruments
- Heavy-duty construction provides protection from dirt, dust, oil and water.
- Sloping front control and instrument panels provide an ideal surface for mounting operator controls or instrumentation.
- Interior mounting is provided for with a removable inner panel located on the rear of the basic console.

### Standards

- UL 508A Type 12
- CSA Type 12
- Complies with**
  - NEMA Type 12
  - IEC 60529, IP65

### Base Console Construction

- Formed 14 gauge steel.
- Smooth, continuously welded seams, without knockouts, cutouts or holes.
- Sloped front instrument panel is continuously hinged on the front (bottom) edge and secured with captive panel screws, threaded into sealed wells.
- Front instrument panel may be removed by pulling the hinge pin.
- Flush doors are secured with a three point latch and operated with a key locking automotive type handle.
- Two door model has overlapping front doors, with three point latch on right door.
- Oil resistant gaskets are permanently secured.
- Includes a removable inner panel formed from 12 gauge steel, mounted to the back of the enclosure interior.
- Collar studs are provided for mounting inner panels.
- A bonding stud is provided on the door and a grounding stud is provided in the enclosure for each door.
- A literature pocket is provided.

### Turret Construction

- Formed and welded from 14 gauge steel.
- Sloping instrument panel and vertical rear access are completely removable.
- Captive panel screws fasten into sealed wells.

### Writing Surface Construction

- Formed and welded from 14 gauge steel.
- Fastens to the front of the console with screws

### Finish

- Cover and enclosure are phosphatized and finished in ANSI 61 gray powder coating on the outside and on the inside.
- Removable inner panels are finished in white powder coating.

## Accessories

- Door Stop Kit
- Window Kits
- Lighting
- Type 12 Handle Kits
- Climate Control
- General Accessories

## New and improved PDF part drawing files with more detail now available.

Click part number in table below to access PDF, DXF, and STEP files.

### Base Console

| Part No.               | Enclosure |       |       |       |       | Panel |       |
|------------------------|-----------|-------|-------|-------|-------|-------|-------|
|                        | H1        | H2    | W     | D1    | D2    | H     | W     |
| 1472-24 <sup>1</sup>   | 36.00     | 40.00 | 24.00 | 17.00 | 20.00 | 18.75 | 27.25 |
| 1472-36 <sup>1</sup>   | 32.00     | 36.00 | 36.00 | 20.00 | 24.00 | 30.00 | 32.00 |
| 1472-48 <sup>1,2</sup> | 32.00     | 36.00 | 48.00 | 20.00 | 24.00 | 42.00 | 32.00 |

<sup>1</sup> UL Listed

<sup>2</sup> 2 Door Version

### Turret

| Part No. | H     | W     | D1    | D2   |
|----------|-------|-------|-------|------|
| 1472-24T | 16.00 | 24.00 | 5.00  | 3.00 |
| 1472-36T | 20.00 | 36.00 | 10.00 | 6.00 |
| 1472-48T | 20.00 | 48.00 | 10.00 | 6.00 |

### Writing Surface

| Part No. | H    | W     | D     |
|----------|------|-------|-------|
| 1472-24W | 4.00 | 24.00 | 10.00 |
| 1472-36W | 4.00 | 36.00 | 10.00 |
| 1472-48W | 4.00 | 48.00 | 10.00 |

Tags: **console, cabinet, Type 12, controls, interface, sloped front, hinged cover, heavy duty, writing, turret**

*Data subject to change without notice*