




Quality Products. Service Excellence.

## Adjustable Depth Wall Rack with Shelf APBS Series

Load rated to 100 lbs (45 kg)

TOP SELLER

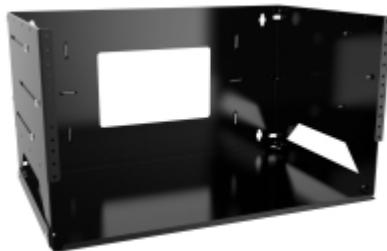

### Features

- Available in 4U and 8U mounting heights. Both sizes include 3.5" (2U) of space for non-rack mounting equipment.
- A twelve (12) inch depth accessory shelf is included.
- The rails vary in depth from 12" to 18" with ease, eliminating the need to disassemble the entire rack.
- Multiple tie points for cable management and rear cable access.
- Self-squaring design ships un-assembled (some assembly required).

### Specifications



Rack Mounting  
Hardware Included



- Constructed in 14-gauge steel.
- The 14-gauge steel mounting rails are threaded 10-32 and contain rack unit indicators.
  - SCREW1032-25, 25-pack of 10-32 mounting hardware included.
- 100 lbs (45 kg) static load rating.
- Finished in RAL9005 black powder paint. Complies with the Greenguard guidelines for indoor air quality.
- TAA-compliant for federal GSA schedule purchases within the USA.
- RoHS Compliant.
- Manufactured in North America within an ISO 9001:2015 certified facility.

### Accessories

• Universal Rack Shelf	• Cable Managers
• Rack Panels	• Hook and Loop Convenience Roll
• 10-32 Mounting Hardware	• We Manufacture PDUs and Outlet Strips
• Ground Stud Kit	



Part No.	Overall Dimensions		Rack		Mounting Dimensions		
	Height	Width	Units	Height	Width	Min Depth	Max Depth
APBS194UBK	10.54	19.25	4U	7.00	19.00	12.00	18.00
APBS198UBK	17.46	19.25	8U	14.00	19.00	12.00	18.00

## What's Inside the Box

Qty Included	Description	Replacement Part No.
1	Rear wall-mounting section	
1	Left side section	
1	Right side section	
2	Sliding Rails	
1	Shelf/Cover	
25	10-32 x 0.75in Rack Mounting Screws	SCREW1032-25
10	10-32 x 3/8 Assembly hardware	
1	Assembly Instructions	

Tags: **Hub-Shelf, Hub Shelf, knock-down, knock down, HA8UWBS, HA4UWBS, wall rack shelf**

*Data subject to change without notice*

© 2026. Hammond Manufacturing Ltd. All rights reserved.