




Quality Products. Service Excellence.

Modular Server/Network Cabinet *C4 Series*

UL2416 rated to 3,000 lbs (1,360 kg).

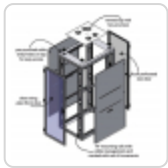

When you prefer complete flexibility, our modular C4 enclosed data rack allows you to select every feature. We can ship the components to you for assembly*, we can assemble the cabinet for you, or you can choose from some of our popular **pre-assembled cabinets here**.

Available Options Include:

- 24U, 42U and 44U mounting heights.
- 24" and 30" overall frame widths.
 - 24" wide frame includes generous cabling space and four (4) 3.5" wide cable entry holes on the top.
 - 30" wide frame includes extra generous cabling space and support for up to four optional vertical cable managers
- 31.5", 36", and 42" overall frame depths.
- All frames include four (4) leveling feet and support optional casters.
- 19" and 23" mounting rails are available in square-hole punched, drilled, and tapped 10-32.
- Flush-mounted doors with quarter-turn lock available in solid, **acrylic window**, vented full or split/barn.
- Side panels are available in both solid and vented for thermal induction.
- One (1) interchangeable top panel opening; is available in solid, vented fan tops with or without fans installed.
- One (1) interchangeable bottom panel opening, available in solid.
- Vertical cable managers are available in tray, enclosed metal, or finger versions.

Specifications

- Welded cabinet frame is 14-gauge steel with 12-gauge steel reinforced corner brackets.
- Cabinet doors and side panels are constructed in 16-gauge steel.
- 19" mounting rails are constructed in 12-gauge steel (square hole punched) or 10-gauge steel (drilled and tapped 10-32).
 - Rails include rack unit indicators and are Zinc-plated to provide superior surface areas for equipment grounding.
 - C-channel struts provide cabinet strength, ease, and flexibility to adjust mounting rails.
- The cabinet is **UL Listed 2416 load rated** to 3,000 lbs (1,360 kg) when assembled with a minimum of two (2) pairs of rails and shipped by Hammond factory. Individual C4 components are not rated.
- Seismic rated up to 1,200 lbs (544 kg) of dynamic load with an Ip factor of 1.5 in accordance with the IBC 2018, CBC 2019, NBC 2018, ASCE 7-16, and ASCE 7-10. Requires a seismic bolt-down kit such as the **C4K-Z4** (sold separately).
- Optional eye-bolts provide a lifting capacity of 1,500 lbs (680.39 kg).
- 1/2-20 Bonding collar studs are provided in frame (4x inner top and 2x bottom side of frame). Additional 10-32 studs are included on compatible side panels and doors.
- Finished in textured RAL9005 black powder paint. Complies with the Greenguard guidelines for indoor air quality.
- Meets PCI DSS (Payment Card Industry Data Security Standard) compliance requirements.



The doors hinge from right-to-left.

To hinge from left-to-right, order the **C4RHINGE** kit.

Accessories

- Server Cabinet Top Panels
 - Open Frame Rack and Rack Cabinet
- Side Panel Locking Kit
 - Cabinet Door Replacement Lock
- Joining Kit
- Universal Rack Shelf
 - Adjustable Server Rack Shelf
 - Sliding Keyboard Shelf
 - Adjustable Depth Front-To-Rear Cable
- Rack Mount Locking Storage Drawer
 - Rack Mount Sliding Shelf
 - Rack Unit Label
 - Horizontal Lacing Strip
- Cable Manager
- Horizontal Ring Cable Manager
 - Cable Management Arm
 - Vertical Cable Tray
 - C4 Server Cabinet Cable Manager
 - Rack Panels
 - Hardware for Rack Mounting Solutions
 - Bolt Down Kit
- Horizontal Steel Finger Cable Manager
 - Horizontal Hinged Cable Manager
 - C4 Server Cabinet Finger Cable Manager
 - We Manufacture PDUs and Outlet Strips
 - Bonding and Grounding
 - Rack and Cabinet Caster Set

C4 Open Frames and Rail Options

Part No.	Overall Dimensions			Rack Units	Usable Mounting Dimensions		19" Rack Rails (Pairs)		23" Rack Rails (Pairs)	
	Height	Width	Depth		Height	Depth	Tapped 10-32	Square Hole	Tapped 10-32	Square Hole
C4F244231BK1	48.58	24.00	31.50	24U	42.00	29.50	-	C4PR2442SZPL	-	-
C4F244236BK1	48.58	24.00	36.00	24U	42.00	34.00	-	C4PR2442SZPL	-	-
C4F244242BK1	48.58	24.00	42.00	24U	42.00	40.00	-	C4PR2442SZPL	-	-
C4F247331BK1	80.08	24.00	31.50	42U	73.00	29.50	C4PR2473TZPL	C4PR2473SZPL	-	-
C4F247336BK1	80.08	24.00	36.00	42U	73.00	34.00	C4PR2473TZPL	C4PR2473SZPL	-	-
C4F247342BK1	80.08	24.00	42.00	42U	73.00	40.00	C4PR2473TZPL	C4PR2473SZPL	-	-
C4F247731BK1	83.58	24.00	31.50	44U	77.00	29.50	C4PR2477TZPL	C4PR2477SZPL	-	-
C4F247736BK1	83.58	24.00	36.00	44U	77.00	34.00	C4PR2477TZPL	C4PR2477SZPL	-	-
C4F247742BK1	83.58	24.00	42.00	44U	77.00	40.00	C4PR2477TZPL	C4PR2477SZPL	-	-
C4F307731BK1	83.58	30.00	31.50	44U	77.00	29.50	C4PR77TZPL	C4PR77SZPL	C4PR7723TZPL	C4PR7723SZPL
C4F307736BK1	83.58	30.00	36.00	44U	77.00	34.00	C4PR77TZPL	C4PR77SZPL	C4PR7723TZPL	C4PR7723SZPL
C4F307742BK1	83.58	30.00	42.00	44U	77.00	40.00	C4PR77TZPL	C4PR77SZPL	C4PR7723TZPL	C4PR7723SZPL

Overall height includes leveling feet. Note that mounting rails are not included with the frame.

C4 Surface Doors with Locking Swing Handle (Hinged on Left)

Part No. Solid	Part No. Window	Part No. Vented	Part No. Vented Split (Barn)	Use with Cabinet	
				Rack Units	Width
C4D2442SBK1	C4D2442WBK1	C4D2442VBK1	C4D2442BBK1	24U	24.00
C4D2473SBK1	C4D2473WBK1	C4D2473VBK1	C4D2473BBK1	42U	24.00
C4D2477SBK1	C4D2477WBK1	C4D2477VBK1	C4D2477BBK1	44U	24.00
C4D3077SBK1	C4D3077WBK1	C4D3077VBK1	C4D3077BBK1	44U	30.00

*Perforated doors for both front and back of the cabinet are suggested for most server applications.

C4 Flush Doors with Quarter-Turn Lock (Hinged on Left)

Part No. Solid	Part No. Window	Part No. Vented	Part No. Vented Split (Barn)	Use with Cabinet	
				Rack Units	Width
C4DF2442SBK1	C4DF2442PBK1	C4DF2442VBK1	C4BD2442VBK1	24U	24.00
C4DF2473SBK1	C4DF2473PBK1	C4DF2473VBK1	C4BD2473VBK1	42U	24.00
C4DF2477SBK1	C4DF2477PBK1	C4DF2477VBK1	C4BD2477VBK1	44U	24.00
C4DF3077SBK1	C4DF3077PBK1	C4DF3077VBK1	C4BD3077VBK1	44U	30.00

C4 Side Panels (Sold in Pairs)

Part No. Solid	Part No. Vented	Use with Cabinet	
		Rack Units	Depth
C4SP4231SBK1	C4SP4231VBK1	24U	31.50
C4SP4236SBK1	C4SP4236VBK1	24U	36.00
C4SP4242SBK1	C4SP4242VBK1	24U	42.00
C4SP7331SBK1	C4SP7331VBK1	42U	31.50
C4SP7336SBK1	C4SP7336VBK1	42U	36.00
C4SP7342SBK1	C4SP7342VBK1	42U	42.00
C4SP7731SBK1	C4SP7731VBK1	44U	31.50
C4SP7736SBK1	C4SP7736VBK1	44U	36.00
C4SP7742SBK1	C4SP7742VBK1	44U	42.00

C4 Top Panels

Part No. Solid	Part No. Vented	Part No. Fan Cutout/ Cable Entry	Part No. Fan Vents	Part No. Four (4) 4.7" 100CFM Fans With Thermostat	Part No. One (1) 10" 550 CFM Fan Without Thermostat	Use with Cabinet	
Top Panel	Top Panel	Top Panel	Top Panel	Top Panel	Top Panel	Width	Depth
C2T1923SBK1	C2T1923VBK1	C2T1923FBK1	C2T1923VFBK1	C2T1923F4TBK1	C2T1923F10BK1	24.00	31.50
C2T1931SBK1	C2T1931VBK1	C2T1931FBK1	C2T1931VFBK1	C2T1931F4TBK1	C2T1931F10BK1	24.00	36.00
C2T1936SBK1	C2T1936VBK1	C2T1936FBK1	C2T1936VFBK1	C2T1936F4TBK1	C2T1936F10BK1	24.00	42.00
C2T2423SBK1	C2T2423VBK1	-	C2T2423VFBK1	C2T2423F4TBK1	C2T2423F10BK1	30.00	31.50
C2T2431SBK1	C2T2431VBK1	-	C2T2431VFBK1	C2T2431F4TBK1	C2T2431F10BK1	30.00	36.00
C2T2436SBK1	C2T2436VBK1	-	C2T2436VFBK1	C2T2436F4TBK1	C2T2436F10BK1	30.00	42.00

C4 Bottom Panel

Solid Part No.	Brushed Part No.	Use with Cabinet	
		Width	Depth
C4B2431SBK1	C4BBCE2431BK1	24.00	31.50
C4B2436SBK1	C4BBCE2436BK1	24.00	36.00
C4B2442SBK1	C4BBCE2442BK1	24.00	42.00
C4B3031SBK1	C4BBCE3031BK1	30.00	31.50
C4B3036SBK1	C4BBCE3036BK1	30.00	36.00
C4B3042SBK1	C4BBCE3042BK1	30.00	42.00

C4 Vertical Cable Manager

Cable Tray	Cable Tray with Toolless PDU Bracket	Metal Manager with Hinged Door	Finger Manager (30" wide version comes with door)	Use with Cabinet	
				Rack Units	Width
VCT42	-	-	-	24U	24.00
VCT73	VCTPDU73	-	C4VFM42UBK	42U	24.00
VCT77	VCTPDU77	-	C4VFM44UBK	44U	24.00
VCT42	-	-	-	24U	30.00
VCT73	VCTPDU73	-	C4VFMC3042UBK	42U	30.00
VCT77	VCTPDU77	C4VCM77BK1	C4VFMC3044UBK	44U	30.00

C4 Right-Hand Hinge

Part No.	C4RHINGE
----------	----------

Split Door Retrofit Kit

Part No.	SDRK
----------	------

Data subject to change without notice

© 2026. Hammond Manufacturing Ltd. All rights reserved.