



Quality Products. Service Excellence.


## Partial Height Door Support CPDS Series

For use with the C2 cabinet series only.

### Features



- Allows partial height flush door installation.
- Requires drilling of rack frame
- Occupies 1.75" (1U) of panel height
- Door support is 0.75" deep
- Constructed of 14 gauge steel.
- Finished in textured RAL9005 black powder paint coat.
  - Complies with the Greenguard guidelines for indoor air quality.
- TAA-compliant for GSA Schedule purchases.
- RoHS and REACH compliant.
- Manufactured in North America.

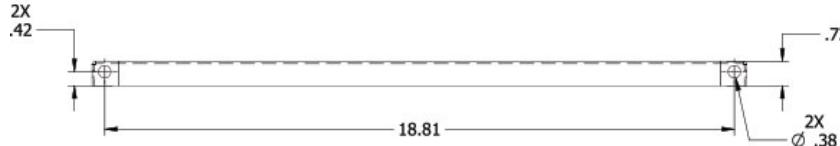

Part No.	Overall Dimensions			Mounting Dimensions		Rack Units	
	Black	Height	Width	Depth	Height	Width	
CPDS19BK1		1.73	19.56	0.73	1.75	19.00	1U



Data subject to change without notice

© 2026. Hammond Manufacturing Ltd. All rights reserved.