




Quality Products. Service Excellence.


Centered Rack Shelf DNDM Series

Load rated to 200 lbs (91 kg)

Features

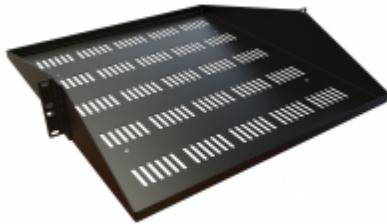

- 16-gauge steel construction.
- The vented version provides a sturdy shelf while allowing passive airflow.
- Rugged textured black powder paint finish.
- The solid version is available in either 19" or 23" rack mounting width.
- 200 lbs (91 kg) load rating.
- Finished in textured RAL9005 black powder coat. Complies with the Greenguard guidelines for indoor air quality.
- TAA-compliant for federal GSA schedule purchases within the USA.
- RoHS and REACH compliant.
- Manufactured in North America.

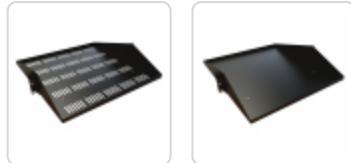

Accessories

- Hardware for Rack Mounting Solutions
- Rack Rail Reducer Panel
- Hook and Loop Convenience Roll



19" Mounting

Part No.		Overall Dimensions	Rack	Mounting	
Vented	Solid	Height	Depth	Units	Width
-	DNDMS1916BK1	3.50	16.00	2U	19.00
DNDMV1918BK1	DNDMS1918BK1	3.50	18.00	2U	19.00
DNDMV19BK1	DNDMS19BK1	3.50	19.50	2U	19.00
-	DNDMS1920BK1	3.50	20.00	2U	19.00
-	DNDMS1922BK1	3.50	22.00	2U	19.00
-	DNDMS1924BK1	3.50	24.00	2U	19.00

23" Mounting

Part No.		Overall Dimensions	Rack	Mounting
Solid Only	Height	Depth	Units	Width
DNDMS23BK1	3.50	19.50	2U	23.00

Data subject to change without notice

© 2026. Hammond Manufacturing Ltd. All rights reserved.