



Quality Products. Service Excellence.

## Type 12 Mild Steel Miniature Pushbutton Enclosures MPB Series




### Application

- Designed to accept 22mm miniature oil tight pushbuttons, switches and pilot lights.
- Provides protection from dirt, dust, oil and water.

### Standards

- UL 508A Type 12 and 13
- CSA Type 12 and 13
- **Complies with**
  - NEMA Type 12 and 13
  - IEC 60529, IP54
- Appropriate components are required to maintain these standards.

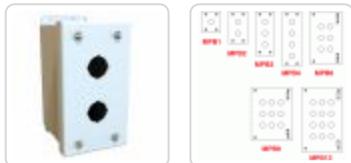

### Construction

- Formed 16 gauge steel.
- Smooth continuously welded seams.
- Welded brackets provide for enclosure mounting.
- Captive cover screws thread into sealed wells.
- Larger enclosures provide internally hinged removable covers, designed to hold the cover open during wiring (see table).
- Oil resistant gasket and adhesive.
- A bonding stud is provided on the door and a grounding stud is provided on the enclosure.



### Finish

- Offered in 2 colors - Cover and enclosure are phosphatized and finished in (a) ANSI 61 gray or (b) RAL7035 light gray powder coating.

### Accessories

- Hole Plugs
- General Accessories
- Pedestal and Base

**New and improved PDF part drawing files with more detail now available.**

Click part number in table below to access PDF, DXF, and STEP files.

ANSI 61 Gray Part No.	RAL7035 Light Gray Part No.	No. of Holes	Enclosure		
			H	W	D
MPB1 <sup>1</sup>	MPB1LG <sup>1</sup>	1	3.25	2.75	3.50
MPB2 <sup>1</sup>	MPB2LG <sup>1</sup>	2	5.13	2.75	3.50

ANSI 61 Gray Part No.	RAL7035 Light Gray Part No.	No. of Holes	Enclosure		
MPB3 <sup>1</sup>	MPB3LG <sup>1</sup>	3	7.00	2.75	3.50
MPB4 <sup>1</sup>	MPB4LG <sup>1</sup>	4	8.88	2.75	3.50
MPB6	MPB6LG	6	8.50	5.00	4.25
MPB9	MPB9LG	9	8.50	6.50	4.25
MPB12	MPB12LG	12	10.38	6.50	4.25

<sup>1</sup> Not hinged

Tags: **pushbutton, Type 12, button, dial, switch, pilot light, 22mm**

*Data subject to change without notice*

© 2026. Hammond Manufacturing Ltd. All rights reserved.