




Quality Products. Service Excellence.

## Adjustable-Depth Rackmount Angle Bracket RAAB Series

Load rated to 200 lbs (91 kg)

TOP SELLER

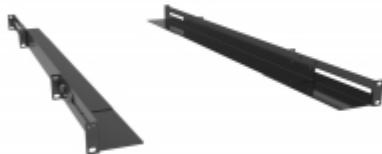

The Rackmount Adjustable Angle Bracket (RAAB) accommodates the weight of heavy equipment that isn't installed on a rack. The RAAB, which comes in two depth ranges, can support up to 200 lbs and vary from 24 to 48 inches deep.

### Features

- Constructed in 16-gauge steel.
- Angles mount to 19", 23", or 24" EIA rack mounting rails.
- Requires two pairs of mounting rails.
- Designed to support equipment such as servers, switchgear, and computer/server chassis on their side.
- The free-floating design easily adjusts in depth to accommodate different equipment dimensions.
- Two adjustable depth options.
- **Sold in pairs.**
- Requires mounting hardware.
- 200 lbs (91 kg) **load rating**.
- Finished in smooth RAL9005 black powder coat. Complies with the Greenguard guidelines for indoor air quality.
- TAA-compliant for federal GSA schedule purchases within the USA.
- RoHS Compliant.
- Manufactured in North America within an ISO 9001:2015 certified facility.



### Accessories

- Hardware for Rack Mounting Solutions
- Rack Equipment Installation Tool



Part No.	Height	Width	Overall Dimensions		Rack Units
			Min Depth	Max Depth	
RAAB2436BK	1.72	3.14	23.70	36.00	1U
RAAB3648BK	1.72	3.14	35.70	48.00	1U

Tags: **Equipment Support Frame, Variable depth**

*Data subject to change without notice*

© 2025. Hammond Manufacturing Ltd. All rights reserved.