




# MUELLER®

## DATASHEET

### C3BD80UXXX

(Mueller Blue-Flex™, M12 Cordset, 3 Position, 22 AWG, Male Right-Angle to Female Right-Angle)

**Mueller Blue-Flex™**

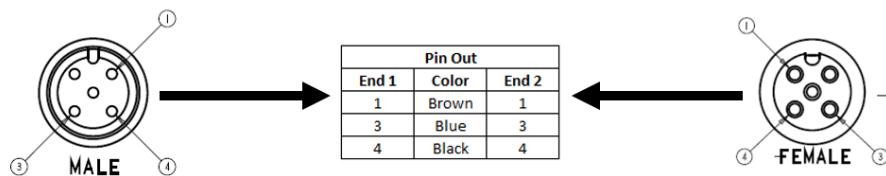

- Mueller's C3BD80UXXX is part of Mueller Blue-Flex's™ instrumentation cable offering. The cable is an M12 with a right-angle male connector on one end and female right-angle on the other.
- Keyway – A coding
- Utilizes the Mueller Blue-Flex™ cable – 3 conductor, 22AWG, unshielded, silicone outer jacket and inner conductor jacket for maximum flexibility.
- Ratings:
  - Current: 4A
  - Voltage: 250 V AC/DC
- Material
  - Coupling Nuts (anti-vibration) – Nickel Plated Brass (also available in stainless steel)
  - Pins/Contacts – Gold Plated Brass
- Length: The "U" in the model number represents unit of measurement.  
Either: Meters (M), Feet (F)
- Length: The "XXX" in the model number represents length. Standard lengths are 2, 5, and 10 meters. Any other lengths available upon request.
- Meets Standard: IEC 61076-2-101
- Protection Class: IEC IP68
- RoHS 3 Compliant