


C4C24UXXX

(M12 Cordset, 4 Position, 24 AWG, Shielded Female Straight to Free End)

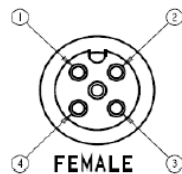

Pin Out		
End 1	Color	End 2
1	Brown	Free End
2	White	
3	Blue	
4	Black	

- Mueller's C4C24UXXX is a shielded, M12 4-pin single ended instrumentation cable with a straight female connector on one end and free at the other.
- Keyway – A Coding
- Utilizes a 4-conductor 24 AWG, PVC-insulated, shielded cable.
- Ratings:
 - Current: 4 A
 - Voltage: 250 V AC/DC
- Material:
 - Coupling Nuts – Nickel Plated Brass
 - Pins/Contacts – Gold Plated Brass
- Length: The "U" in the model number represents unit of measurement.
Either: Meters (M), Feet (F)
- Length: The "XXX" in the model number represents length. Standard lengths are 2, 5, and 10 meters. Any other lengths available upon request.
- Meets Standard: IEC 61076-2-101
- Protection Class: IEC IP68
- RoHS 3 Compliant