


T-1 3/4 MIDGET FLANGE BASE LED

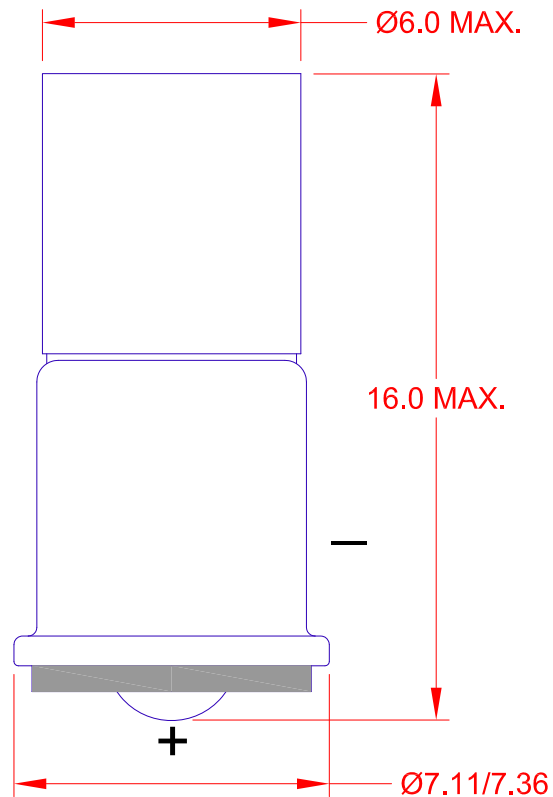

JKL PART NUMBER	EMITTING COLOR	AMPERAGE mA	VOLTAGE Vdc	LUMENS	VIEWING ANGLE
LE-MF-12W	WHITE	15	12	3.5	40°
LE-MF-24W	WHITE	15	24	3.5	40°

OPERATING TEMPERATURE RANGE -30°C TO +85°C

STORAGE TEMPERATURE RANGE -40°C TO +100° C

NOTES:

1. LED includes integrated diode for reverse voltage protection.
2. LED includes integrated resistor for current limiting.

			METRIC  THIRD ANGLE PROJECTION	DIMENSIONS ARE IN MILLIMETERS TOLERANCE UNLESS OTHERWISE SPECIFIED 1 PL +/- 0.2 2 PL +/- 0.20 ANGLE +/- 0	JKL COMPONENTS CORPORATION TITLE T-1 3/4 MIDGET FLANGE BASE LED												
				DRAWN BY	APPV'D BY	DATE	SIZE	FSCM NO.	DRAWING NO.	LE-MF MULTI							
				L. WENGSTROM	L.R.	6/13/12	A	55335									
	RELEASED		6/13/12	- CAD DRAWING - MANUAL REVISIONS NOT PERMITTED			SCALE	NONE		RELEASED DATE	6/13/12	REVISION DATE		REV. NO.		SHEET	1 OF 1
REV. NO.	DESCRIPTION/ECO NUMBER		APPV'D DATE														