
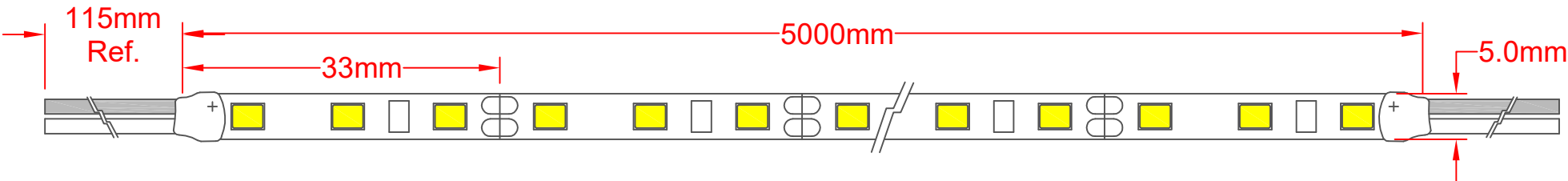


LED FLEX RIBBON

FEATURES:

- 12 Vdc LED Flex Ribbon
- 5600°K ± 500° K Cool White
- LED Count: 90 LEDs per meter
- 3 LEDs per section (33mm) with solder pads
- Double-sided tape on backside of Flex Ribbon
- Operating Temperature Range -20°C to +60°C
- Power: 65W per reel

 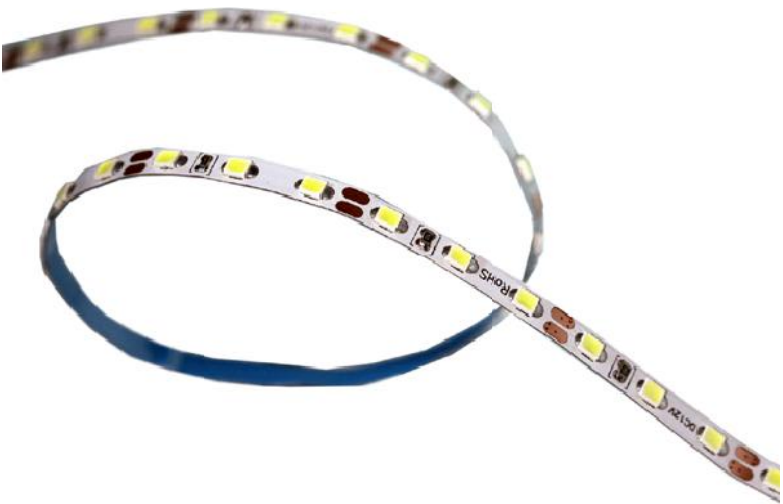


ELECTRO-OPTICAL CHARACTERISTICS

JKL Part Number	Color	Number of LEDs	InputVoltage (TYP.)	InputVoltage (MAX.)	CCT	Lumen Flux (lm)
ZFS-55000-CW	Cool White	450	12	13.2	5600	13-19 Per LED



C	ADD UL	5/11/26
B	LUMEN FLUX CHANGE TO 13-19 PER LED	12/19/18
A	CHANGE PART NO. ADDED FEATURES	3/9/17
	RELEASED	2/22/17
REV. NO.	DESCRIPTION/ECO NUMBER	APPV'D DATE

METRIC  THIRD ANGLE PROJECTION		DIMENSIONS ARE IN MILLIMETERS TOLERANCE UNLESS OTHERWISE SPECIFIED 1 PL +/- REF. 2 PL +/- REF. ANGLE +/- REF.		JKL COMPONENTS CORPORATION TITLE 12 VOLT LED FLEX RIBBON									
DRAWN BY L. WENGSTROM		APPV'D BY SN		DATE 5/11/26		SIZE A		FSCM NO. 55335		DRAWING NO. ZFS-55000-CW			
				SCALE NOT TO SCALE		RELEASED DATE 2/22/17		REVISION DATE 5/11/26		REV. NO. C		SHEET 1 OF 1	