


FEATURES

- VOLTAGE: 12 VDC
- CURRENT: 4 A
- WATTAGE: 48 W

STANDARD PACKAGING

- 196.85"/16.5 ft. reel
- 600 LEDs per reel
- Easy Peel and Stick Mounting

 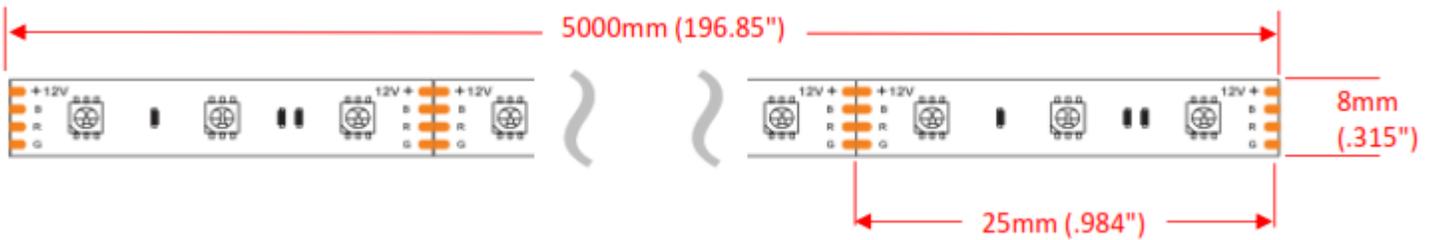


Each 0.984" segment is cuttable and includes 3 LEDs

PARAMETER	COLOR	TYP	UNIT
Forward Voltage DC	RGB	12	V
Dominant Wavelength	Red	624	nm
	Green	518	
	Blue	471	



E365522

			METRIC  THIRD ANGLE PROJECTION		DIMENSIONS ARE IN MILLIMETERS TOLERANCE UNLESS OTHERWISE SPECIFIED 1 PL +/- 0.2 2 PL +/- 0.20 ANGLE +/- 0		JKL COMPONENTS CORPORATION TITLE HIGH DENSITY RGB LED FLEX STRIP			
DRAWN BY S. VELAS			APPVD BY DATE S.N. 11/24/25		SIZE A	FSCM NO. 55335	DRAWING NO. ZFS-85000HD-RGB			
REV. NO. RELEASED	DESCRIPTION/ECO NUMBER 	APPVD DATE 11/24/25	MANUAL REVISIONS NOT PERMITTED			SCALE NONE	RELEASED DATE 11/24/25	REVISION DATE 	REV. NO. 	SHEET 1 OF 1