



SR Series - Safety Rope Pull Switches

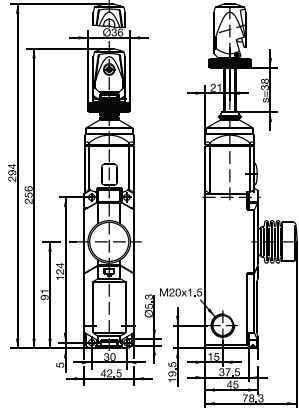

Quick Fix with E-Stop & Reset



Quick Fix with Reset Only

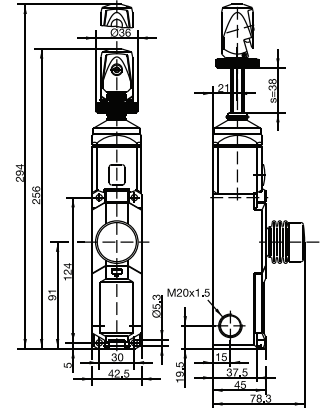

Max. span length

2 NC/2 NO

4 NO

2 NC/2 NO

4 NC

601.1629.067

SR-U2Z-NA-QF-100-L0-0-0

601.1691.077

SR-A4Z-NA-QF-100-L0-0-0

601.1629.070

SR-U2Z-0-QF-100-L0-0-0

601.1691.080

SR-A4Z-0-QF-100-L0-0-0

82 Ft. (25 Meters)

Replaces

601.1629.031
SR-U2Z-NA-QF 100

Replaces

601.1691.052
SR-A4Z-NA-QF 100

Replaces

601.1629.032
SR-U2Z-QF 100

Replaces

601.1691.049
SR-A4Z-QF 100

123 Ft. (37.5 Meters)

601.1629.068

SR-U2Z-NA-QF-175-L0-0-0

601.1691.078

SR-A4Z-NA-QF-175-L0-0-0

601.1629.071

SR-U2Z-0-QF-175-L0-0-0

601.1691.081

SR-A4Z-0-QF-175-L0-0-0

Replaces

601.1629.027
SR-U2Z-NA-QF 175

Replaces

601.1691.053
SR-A4Z-NA-QF 175

Replaces

601.1629.024
SR-U2Z-QF 175

Replaces

601.1691.050
SR-A4Z-QF 175

246 Ft. (75 Meters)

601.1629.069

SR-U2Z-NA-QF-300-L0-0-0

601.1691.079

SR-A4Z-NA-QF-300-L0-0-0

601.1629.072

SR-U2Z-0-QF-300-L0-0-0

601.1691.082

SR-A4Z-0-QF-300-L0-0-0

Replaces

601.1629.019
SR-U2Z-NA-QF 300

Replaces

601.1691.054
SR-A4Z-NA-QF 300

Replaces

601.1629.028
SR-U2Z-QF 300

Replaces

601.1691.051
SR-A4Z-QF 300

Approvals



Technical data

Electrical data		
Rated insulation voltage	U _i max.	250 V AC
Rated operating voltage	U _e max.	240 V
Conventional thermal current	I _{the}	10 A
Utilization category	U _e /I _e	AC-15, U _e /I _e 240 V / 3 A
Short-circuit protection		6 A gL/gG
Protection class		II, Insulated
Mechanical data		
Enclosure	PA 6 GV (UL94-V0)	
Ambient temperature	-25°C to +70°C	
Mechanical service life	100,000 Cycles	
Switching frequency max.	≤ 20 / min.	
Mounting	4 x M5	
B10d	10,000	
Type of connection	Cage clamp terminal	
Conductor cross sections	≤ 1.5 - 2 mm²	
Cable entry	3 x M20 x 1.5	
Protection class	IP67 conforming to IEC/EN 60529	
Standards		
VDE 0660 T100, DIN EN 60947-1, IEC 60947-1 VDE 0660 T200, DIN EN 60947-5-1, IEC 60947-5-1 VDE 0660 T210, DIN EN 60947-5-5, IEC 60947-5-5 ISO 13850		

Drawing dimensions in mm