


SIEM and SID Latching with Reset Button




Pull Cable to change contact state, push button to reset

SIEM2 RAST

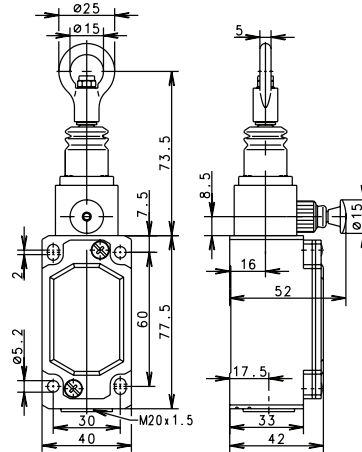


SID RAST

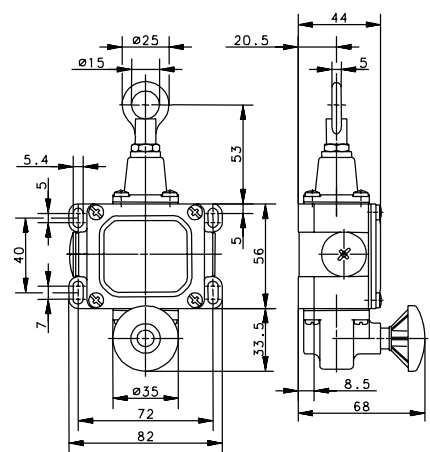


Variant 1

Article No.
Designation
Max. span
Type

 601.2831.023
SIEM2-UV1Z P-RAST
19.6 Ft. (6 Meters)
Metal Body with
Tension Monitor



 
601.1411.868
SD-U1 P-RAST
26.2 Ft. (8 Meters)
Metal Body without
Tension Monitor



Variant 2

Article No.
Designation
Max. span
Type

 
611.1431.060
SID-UV1Z P-RAST
49.2 Ft. (15 Meters)
Metal Body with
Tension Monitor



Variant 3

Article No.
Designation
Max. span
Type

 601.1431.869
SID-UV1Z P-RAST
39.4 Ft. (12 Meters)
Metal Body with
Tension Monitor



Technical Information

Maximum Switching Voltage	240V	240V
Maximum Switching Amperage	10A	16A
B10d	On Request	On Request
Mechanical Service Life	1 x 10 ⁶	1 x 10 ⁶
Switching Frequency	≤ 50/min	≤ 20/min
Operating Temperature	-30 °C to +80 °C	-30 °C to +80 °C
Protection Rating	IP65	IP65
Utilization Category	AC-15, U _e / I _e 240 V / 3 A	AC-15, U _e / I _e 240 V / 3 A
Rate Insulation Voltage	400VAC	400VAC
Approvals		