


SID and SIN Latching with Reset Button




Pull Cable to change contact state, push button to reset

SID RAST

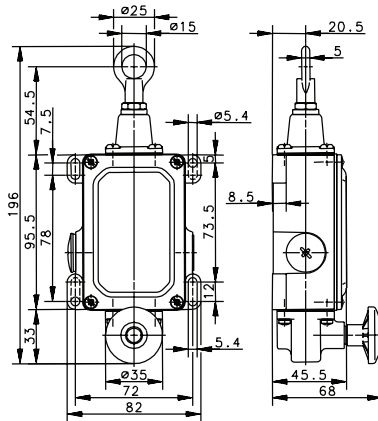


SIN RAST

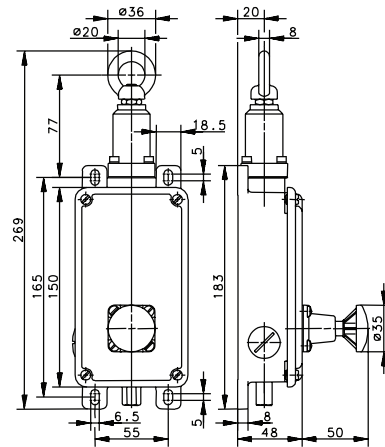


Variant 1

Article No.
Designation
Max. span
Type

 611.2431.050
SID-UV1Z P-RAST
144.8 Ft. (35 Meters)
Metal Body with
Tension Monitor



 601.3531.367
SIN-UV1Z P-RAST
196.8 Ft. (60 Meters)
Metal Body with
Tension Monitor



Variant 2

Article No.
Designation
Max. span
Type

601.2441.907
SID-UV2Z P-RAST
59 Ft. (18 Meters)
Metal Body with
Tension Monitor



Variant 3

Article No.
Designation
Max. span
Type

Technical Information

Maximum Switching Voltage	240V	240V
Maximum Switching Amperage	16A	10A
B10d	On Request	On Request
Mechanical Service Life	1 x 10 ⁶	1 x 10 ⁶
Switching Frequency	≤ 20/min	≤ 20/min
Operating Temperature	-30 °C to +80 °C	-30 °C to +80 °C
Protection Rating	IP65	IP65
Utilization Category	AC-15, U _e / I _e 240 V / 3 A	AC-15, U _e / I _e 240 V / 3 A
Rate Insulation Voltage	400VAC	400VAC
Approvals		

Drawing dimensions in mm