



IF Series



AH

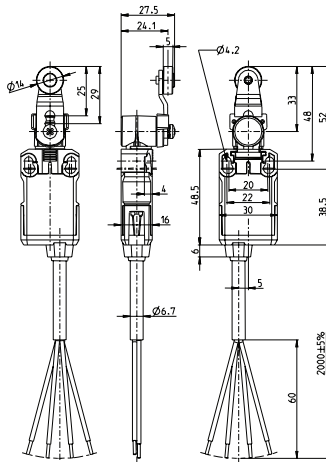

IWF

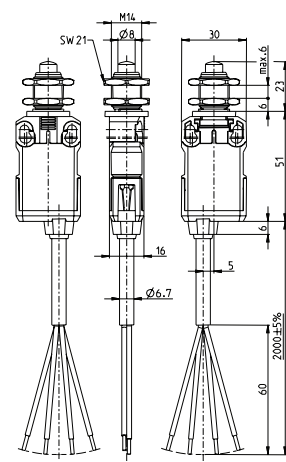


Switching Operation

1 NC / 1 NO Contacts


Slow Action

 608.9135.003
IF-U1Z AH




Snap Action

 608.9185.008
IF-SU1Z AH




Slow Action

 608.9102.004
IF-U1Z IWF




Snap Action

 608.9152.009
IF-SU1Z IWF




2 NC Contacts

 
608.9835.013
IF-A2Z AH



 
608.9885.041
IF-SA2Z AH



 608.9802.014
IF-A2Z IWF



 608.9852.043
IF-SA2Z IWF



2 NO Contacts

-

-

-

-

**1 NC / 1 NO Contacts
Overlapping**

-

-

-

-

Technical Information

Maximum Switching Voltage	240V
Maximum Switching Amperage	10A
B10d	6 Million
Mechanical Service Life	3 x 10 ⁶
Switching Frequency	≤ 30/min
Operating Temperature	-30 °C to +80 °C
Protection Rating	IP67
Utilization Category	AC-15, Ue/Ue 240V 3A
Rate Insulation Voltage	240VAC

Approvals



Slow Action

Snap Action

Special features/variants

- Actuator can be turned in steps of 90°

Slow Action

Snap Action

Special features/variants

- Front mounting

Drawing dimensions in mm