
 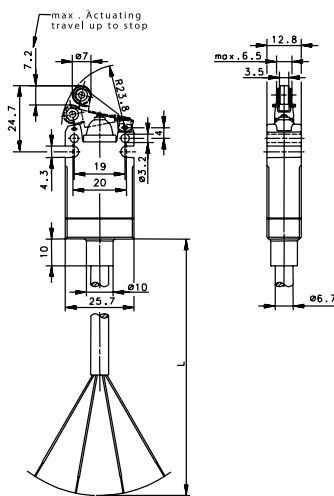
 


EEX RHL

609.0149.027
EEX-SU1Z RHL -2M-

[illegible]

609.0146.012
EEX-SU1 UH -2M-



609.0149.029
EEX-SU1Z RHL -5M-



609.0146.014
EEX-SU1 UH -5M-



—


 || 2 G EEx d || C T6


 II 2 G EEx d IICT6

Maximum Switching Voltage
Maximum Switching Amperage
B10d
Mechanical Service Life
Switching Frequency
Operating Temperature
Protection Rating
Utilization Category
Rate Insulation Voltage

230V
5A
4 Million
2 x 10⁶
≤ 120/min
-20 °C to +65 °C
IP66 / IP67
AC 15, 240 V / 3 A;
DC 13, 250 V / 0.27 A
250VAC

230V
5A
4 Million
 2×10^6
 $\leq 120/\text{min}$
 -20°C to $+65^\circ\text{C}$
IP66 / IP67
AC 15, 240 V / 3 A;
DC 13, 250 V / 0.27 A
250VAC