



I88 Series

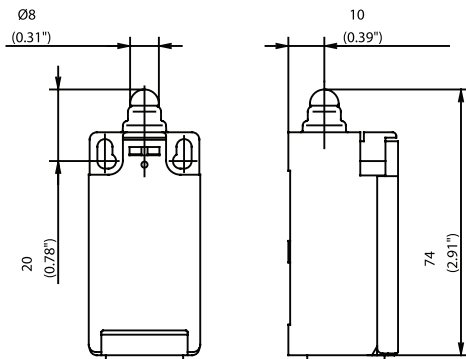

W (Form B)



RIWK (Form C)

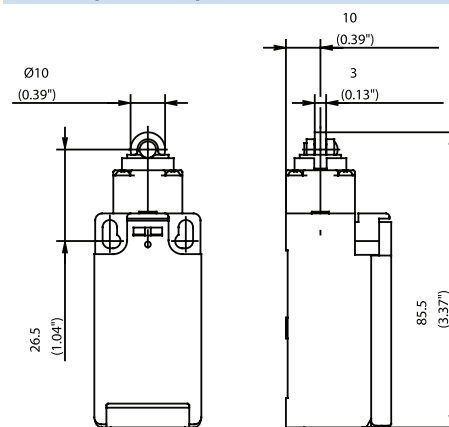


Switching Operation

1 NC / 1 NO Contacts


Slow Action

 608.6103.008
I88-U1Z W




Snap Action

 608.6153.012
I88-SU1Z W




Slow Action

 608.6117.017
I88-U1Z RIWK




Snap Action

 608.6167.018
I88-SU1Z RIWK



2 NC Contacts

 
608.6803.013
I88-A2Z W



-

-

 608.6817.087
I88-A2Z RIWK



-

-

2 NO Contacts

608.6803.014
I88-E2 W



-

-

608.6817.071
I88-E2 RIWK

 


-

-

1 NC / 1 NO Contacts Overlapping

608.6303.011
I88-UV1Z W



-

-

-

-

Technical Information

	Slow Action	Snap Action
Maximum Switching Voltage	240V	240V
Max. Switching Amps (up to)*	10A	10A
B10d (up to)*	20 Million	20 Million
Mechanical Service Life (up to)*	10 x 10 ⁶	10 x 10 ⁶
Switching Frequency	≤ 100/min	≤ 100/min
Operating Temperature	-30 °C to +80 °C	-30 °C to +80 °C
Protection Rating	IP65	IP65
Utilization Category (up to)*	AC-15, Ue/Ue 240V 3A	AC-15, Ue/Ue 240V 3A
Rate Insulation Voltage	250VAC	250VAC

Approvals



Special features/variants (on request)

- Available with black enclosure
- With latching function

Technical Information

	Slow Action	Snap Action
Maximum Switching Voltage	240V	240V
Max. Switching Amps (up to)*	10A	10A
B10d (up to)*	20 Million	20 Million
Mechanical Service Life (up to)*	10 x 10 ⁶	10 x 10 ⁶
Switching Frequency	≤ 100/min	≤ 100/min
Operating Temperature	-30 °C to +80 °C	-30 °C to +80 °C
Protection Rating	IP65	IP65
Utilization Category (up to)*	AC-15, Ue/Ue 240V 3A	AC-15, Ue/Ue 240V 3A
Rate Insulation Voltage	250VAC	250VAC

* Depending on switching system - see technical information for details



Special features/variants (on request)

- Available with steel roller or black enclosure
- With black enclosure
- With latching function

Drawing dimensions in mm