



ENK Series

IW (Form B)

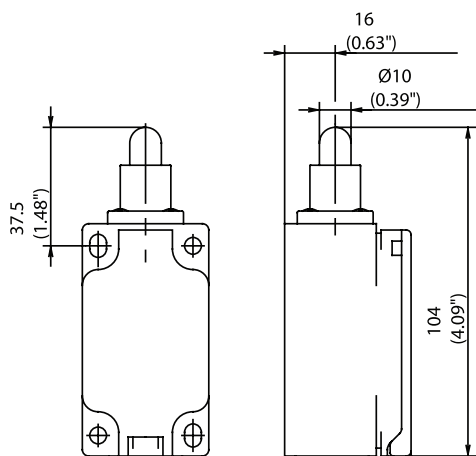

RIW (Form C)

 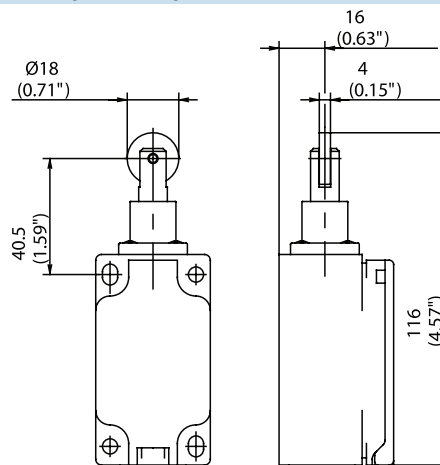


Switching Operation

1 NC / 1 NO Contacts


Slow Action

608.1102.001
ENK-U1Z IW



Snap Action

 608.1152.007
ENK-SU1Z IW



2 NC Contacts

-

-

2 NO Contacts

-

-

1 NC / 1 NO Contacts
Overlapping

-

-

Replacement actuator:

391.8020.660

Technical Information

Slow Action

Snap Action

Maximum Switching Voltage

240V

240V

Max. Switching Amps (up to)*

10A

10A

B10d (up to)*

20 Million

20 Million

Mechanical Service Life (up to)*

10 x 10⁶

10 x 10⁶

Switching Frequency

≤ 100/min

≤ 100/min

Operating Temperature

-30 °C to +80 °C

-30 °C to +80 °C

Protection Rating

IP65

IP65

Utilization Category (up to)*

AC-15, Ue/Ue 240V 3A

AC-15, Ue/Ue 240V 3A

Rate Insulation Voltage

400VAC

400VAC

Approvals

 


Special features/variants (on request)

- Available with black enclosure and following contacts:
3 NC contacts


Slow Action

608.1117.002
ENK-U1Z RIW




Snap Action

 608.1167.008
ENK-SU1Z RIW



 608.1817.281
ENK-A2Z RIW



-

-

608.1317.307
ENK-UV1Z RIW



-

-

391.8170.661

Slow Action

Snap Action

240V

240V

10A

10A

20 Million

20 Million

10 x 10⁶

10 x 10⁶

≤ 100/min

≤ 100/min

-30 °C to +80 °C

-30 °C to +80 °C

IP65

IP65

AC-15, Ue/Ue 240V 3A

AC-15, Ue/Ue 240V 3A

400VAC

400VAC



Special features/variants (on request)

- Available for high temperature range and following contacts:
3 NC contacts

Drawing dimensions in mm