



ENM2 Series

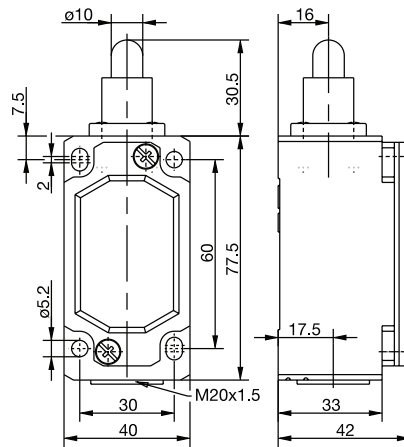

IW (Form B)



RIW (Form C)

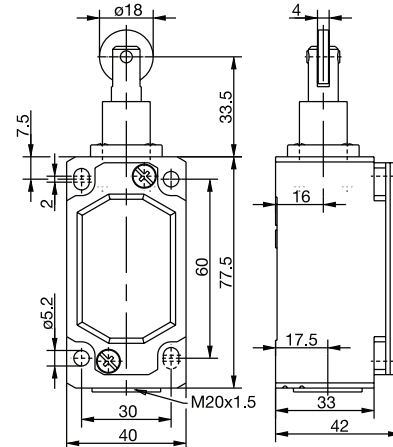


Switching Operation

1 NC / 1 NO Contacts

Slow Action

 608.7102.001
ENM2-U1Z IW




Snap Action

608.7352.002
ENM2-SU1Z IW




Slow Action

 608.7117.004
ENM2-U1Z RIW




Snap Action

 608.7367.005
ENM2-SU1Z RIW



2 NC Contacts

 
608.7802.003
ENM2-A2Z IW




-

-

 608.7817.006
ENM2-A2Z RIW




 608.7867.051
ENM2-SA2Z RIW



2 NO Contacts

 608.7802.021
ENM2-E2 IW



-

-

-

 
-

-

-

1 NC / 1 NO Contacts Overlapping

608.7302.027
ENM2-UV1Z IW



-

-

-

-

-

-

Replacement actuator:

391.8020.584

391.8170.587

Technical Information

Slow Action

Snap Action

Maximum Switching Voltage

240V

240V

Max. Switching Amps (up to)*

10A

10A

B10d (up to)*

20 Million

20 Million

Mechanical Service Life (up to)*

10 x 10⁶

10 x 10⁶

Switching Frequency

≤ 100/min

≤ 100/min

Operating Temperature

-30 °C to +80 °C

-30 °C to +80 °C

Protection Rating

IP65

IP65

Utilization Category (up to)*

AC-15, Ue/Ue 240V 3A

AC-15, Ue/Ue 240V 3A

Rate Insulation Voltage

400VAC

400VAC

Approvals

* Depending on switching system - see technical information for details



Special features/variants (on request)

- Also available with following contacts:
2 NC / 1 NO with overlap
1 NC / 2 NO with overlap

Special features/variants (on request)

- Available with different directions
- High temperature range
- Different roller diameters and contact types

Drawing dimensions in mm