

[Article Page](#)

Product Description

Name

one-way light barrier

Order number

KOES15M-M18MB85-D-V2-IR

Matchcode

08363250230

Illuminant


M18B-T015MD-EX9Q4LE

Connection

IR Infrared light 880 nm

Connection diagramm

 Connector

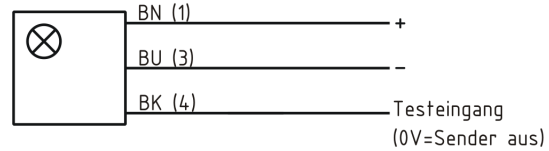

Technical Specification

Signal type

Throughbeam sensor

Operating voltage

10 - 30 V DC

Max. load current

200 mA

No load current

< 30 mA

Operating temperature

-25 ° C to 55 ° C

Digital output

Measuring range

15 m

Sensitivity adjustable

ja

Sensing range adjustable

nein

Short-circuit proof

yes

Overload protection

yes

Reverse voltage protection

yes

Protection category

IP67

EMC-level

DIN EN 60947-5-2:2008

Termination

Connector M12 4pol

Notes

Sender mit Testeingang

Errors and omissions exceptet