
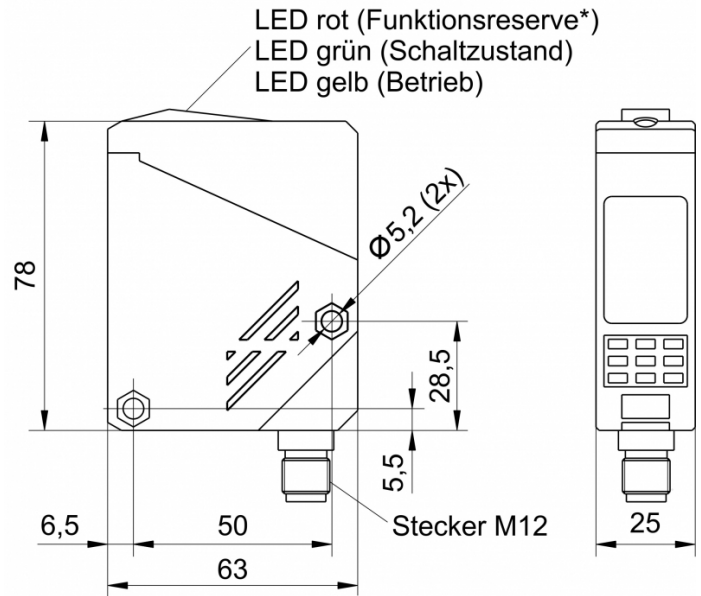


[Article Page](#)

Product Description


one-way light barrier

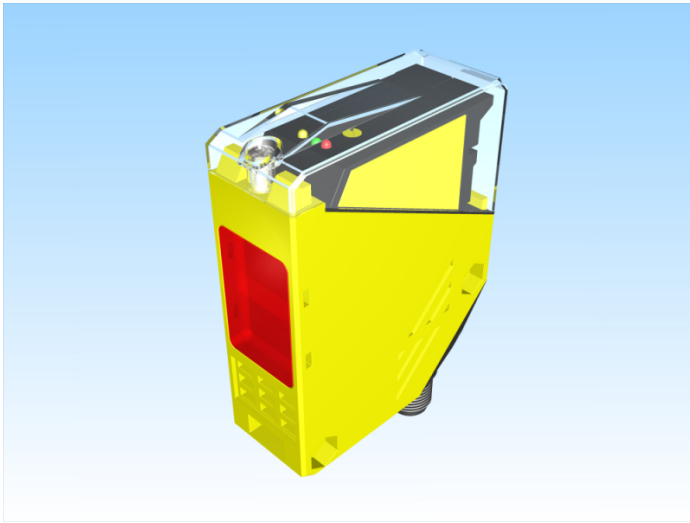

Name
Order number
Signal Type
Illuminant
Connection
Connection diagramm

KOES28M-Q76KB-D-V2-IR
08363280034
Transmitter
IR Infrared light 880 nm
connector M12

Dimension (in mm)
Technical Specification
Signal type
Operating voltage
No load current
Operating temperature
Operating state
Measuring range
Reverse voltage protection
Protection category
EMC-level
Housing material
Termination
Notes

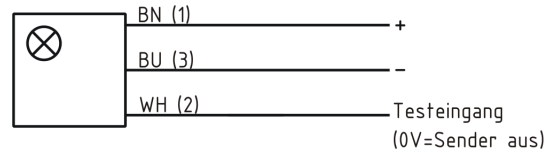

Q 25 x 77.5 x 63

Throughbeam sensor
10 - 30 V DC
< 35 mA
-25 ° C to 55 ° C
LED
28 m
yes
IP67
DIN EN 60947-5-2:2008
Plastic
Connector M12 4pol (pivotal: 0° oder 90°)
Sender mit Testeingang

Errors and omissions exceptet