

[Article Page](#)

Product Description

Name
Order number
Matchcode
Switching distance
Switch type

reflex light probe
KORT200-Q20KB25-DPA-RT
08361205006
UP-D0200P-CX6C4U2-F
200 mm



Changeover


Signal Type
Illuminant
Connection

DC PNP
● Red light 680 nm



Cable

Connection diagramm

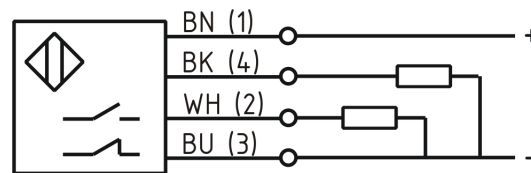

8 x 20 x 25

Dimension (in mm)
Technical Specification
Signal type
Operating voltage
Max. load current
No load current
Switching frequency
Operating temperature
Operating state
Switching state
Digital output
Sensitivity adjustable
Sensing range adjustable
Short-circuit proof
Overload protection
Reverse voltage protection
Protection category
EMC-level
Housing material
Termination

Diffuse mode sensor
10 - 30 V DC
150 mA
< 25 mA
300
-20 ° C to 55 ° C
LED
LED

ja
nein
yes
yes
yes
IP67
DIN EN 60947-5-2:2008
Plastic
2m PVC 4x0,15mm²

Errors and omissions exceptet