
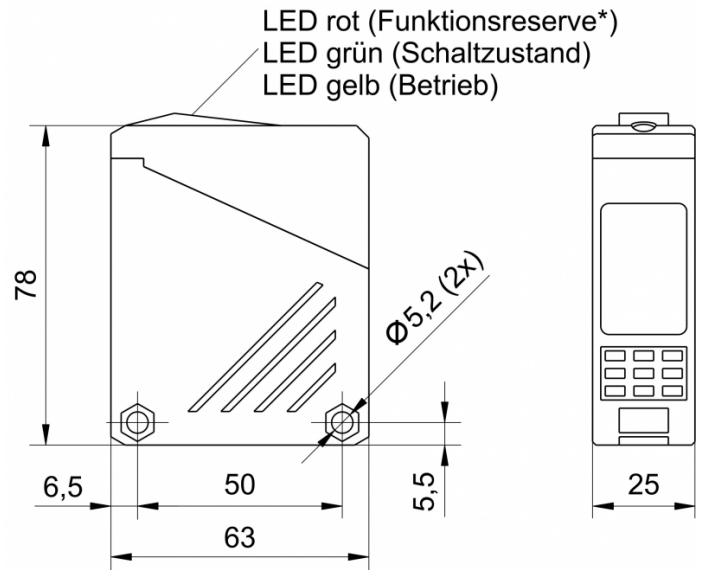


[Article Page](#)

Product Description

reflex light probe

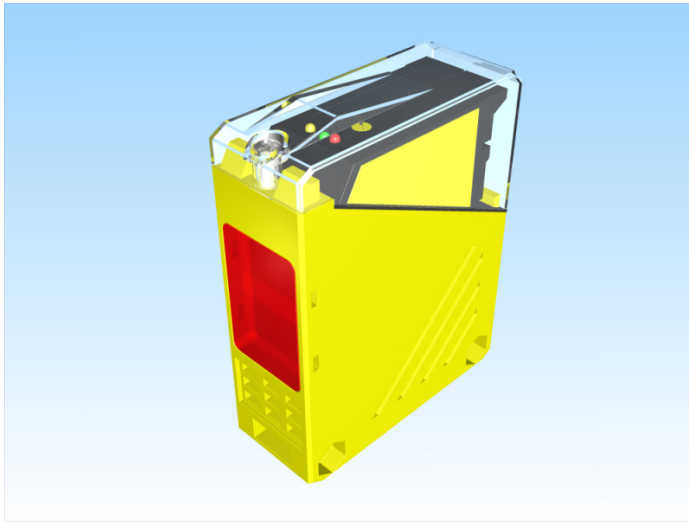


Name
Order number
Switching distance
Switch type

Signal Type
Illuminant
Connection
Connection diagramm

KORT800-Q76KB-VRU-NPT-IR
08361280007
800 mm

 Switchable
Relay
IR Infrared light 880 nm
Terminal

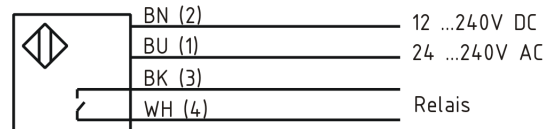

Q 25 x 77.5 x 63

Dimension (in mm)
Technical Specification
Signal type
Operating voltage
Max. load current
No load current
Switching frequency
Operating temperature
Operating state
Switching state
Sensitivity adjustable
Reverse voltage protection
Protection category
EMC-level
Housing material

Diffuse mode sensor
12 - 240 V DC / 24,00 - 240,00 V AC
3 A
< 30 mA
25 Hz
-25 ° C to 55 ° C
LED
LED
ja
yes
IP65
DIN EN 60947-5-2:2008
Plastic

Errors and omissions exceptet